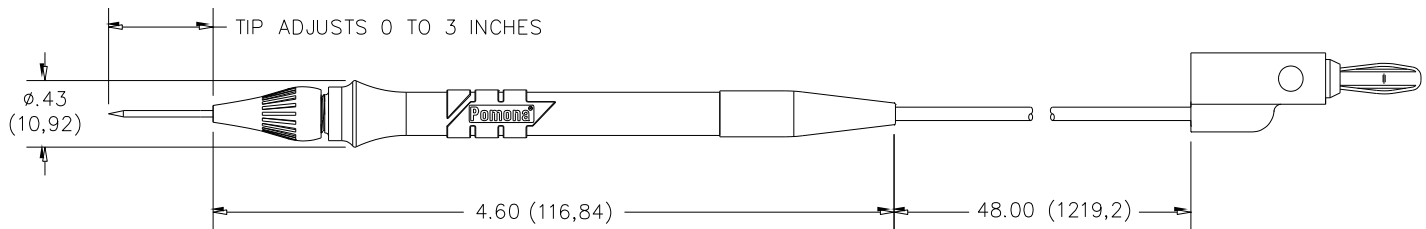


**Model 5952A**  
**Adjustable Tip Test Probe Set****FEATURES**

- Slim retractable probe fully insulated to within 1/8" (3,18) of tip
- Needle point tip adjusts to desired length from 0-3" (0-76mm)
- Stainless Steel needle point easily pierces varnish and thin insulation
- Tip can be re-pointed if necessary
- Multi-stacking Banana plug molded directly on the wire
- Banana plug spring is nickel plated Beryllium Copper for long insertion life
- 4 foot test lead wire is silicone insulated for high temperature resistance and flexibility at low temperature.
- Wear indication with double insulated (dual extruded) silicone leads shows black inner layer for increased safety.

**MATERIALS**

Probe Body: Polypropylene and PVC, color: one black, one red.

Tip: Stainless Steel

Wire: 20 AWG, Silicone insulation

**RATINGS:**

Operating Voltage: 30 Vrms/42.4 Vpk/60 Vdc

Current: 3 Amperes

**ORDERING INFORMATION**

Model 5952A

Includes a set of one black and one red test lead

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844  
**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500  
**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm 0.02$ " (.51 mm), .xxx =  $\pm 0.005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

5952A