

FEATURES:

- ✓ Test tip adapter has been designed to IEC 1010, which is the latest international safety standard.
- ✓ Snaps onto Pomona's DMM Probes with .080" (2 mm) O.D. Tips, such as model 5519A.
- ✓ Adapter allows access to hard to reach test points.
- ✓ Tip is insulated to the point to prevent shorting of adjacent components.

MATERIALS:

Tip: Stainless Steel

Tip Insulation: Kynar

Body: Polypropylene, Fire Retardant, UL94 V-2 Rated, Color: One Red, One Black

RATING:

IEC 1010-2-031, Category II, P2 Compliant

Operating Voltage: 300 Vrms/DC


Current: 3 Amperes.

ORDERING INFORMATION:

Model 6262-02 (set of one black and red probe)

Model 6262-2 (red probe only)

Ordering example: 6262-2 (red probe)

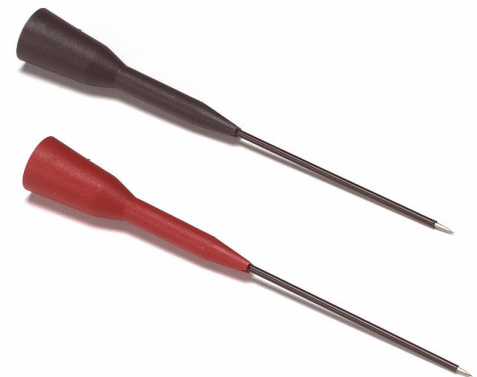

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Sales: 800-490-2361 Fax: 425-446-5844 Technical Support: technicalsupport@pomonatest.com

For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

6262-02 6262-02#