


## Model 6312 & 6352 Micro SMD Grabber® Test Clip With Long Tip For 1.25 MM to 0.3 MM Lead Pitch

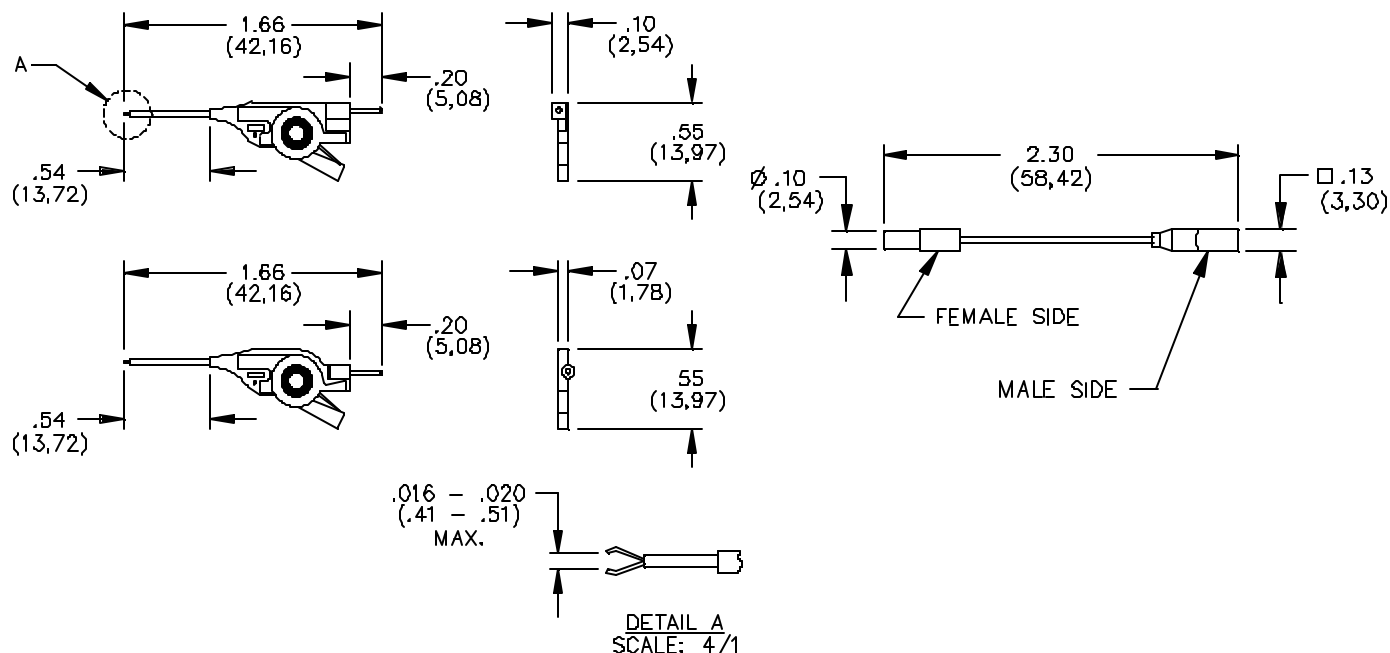

### FEATURES:

- Use with PQFP packages with 0.3mm lead pitch or greater
- 13mm long tip allows measurement at IC leads that are not easily accessible
- Thin body style allows an unlimited number of clips to be stacked side by side
- Maximum frequency is 100 MHz

### MATERIALS:

Teflon™ coated tip: Nickel plated steel wire or stainless steel, Body: ABS

### RATINGS:

Operating Voltage: 30VAC/60VDC

### ORDERING INFORMATION: Model 6312

6352 Kit contains 10 pieces of 6312

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).  
All specifications are to the latest revisions. Specifications are subject to change without notice.  
Registered trademarks are the property of their respective companies. Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

6312