


Model 6341, 6342, 6275
Precision Electronic Probe with Replaceable Tips

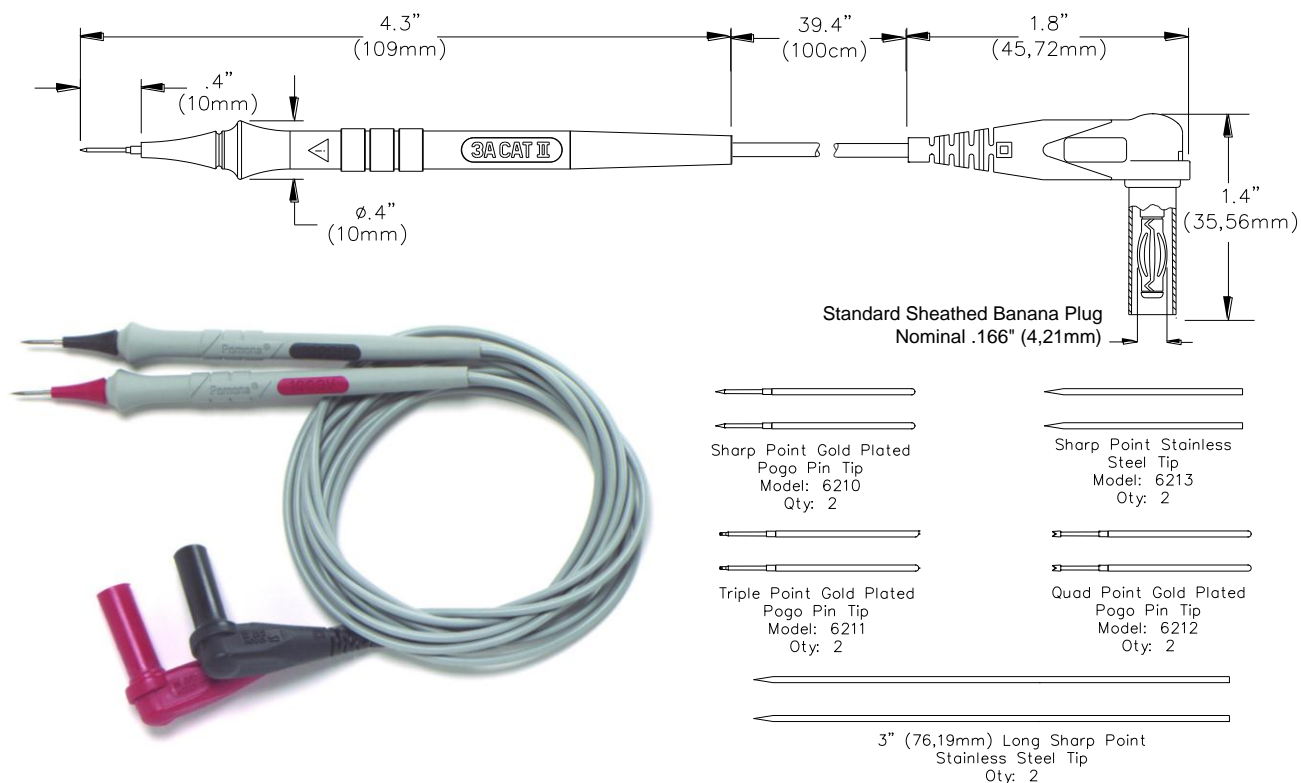

FEATURES:

- Miniature probe is the perfect size for probing tiny, high-density circuits.
- Gold plated pogo pin tip keeps constant pressure on test point for consistent readings.
- Replaceable probe tips.
- Safety design complies with all the latest standards.
- Silicone insulated wire for extreme flexibility and high temperature resistance.
- Wear indication with dual extruded silicone leads shows black inner layer for increased safety.

MATERIALS:

Probe Body: Insulation - Gray Santoprene® Rubber over Polypropylene.
 Right Angle Sheath Banana Plug:
 Plug Body: Nickel Plated Brass.
 Banana Plug Spring: Nickel Plated Beryllium Copper.
 Insulation: Santoprene®
 Wire: 20 AWG, gray silicon rubber 0.089 (2,26mm) O.D.
 Probe Tips: Gold plated or Stainless Steel

RATINGS:

Operating Voltage: IEC 61010-031 CAT II 1000 Vrms Max.

(Note: *The 3" (76,19mm) Long Sharp Point Stainless Steel Tip is rated 30 Vrms/42.4Vpk/60Vdc only.*)

Current: 3 Amperes

ORDERING INFORMATION:

- Model: 6341 (one red probe, one black probe with a set of all tip styles)
 Model: 6342 (one red probe, one black probe with model 6210 sharp point gold pogo pin tips)
 Model: 6275 (one red probe, one black probe with model 6213 sharp point stainless steel tips)
 Model: 6354 (replacement tips only, set of all tips)

USA: Sales: 800-490-2361
 Technical Support: technicalsupport@pomonatest.com
 Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[6275](#) [6354](#) [6341](#) [6342](#)