

MODEL NO.	ATTENUATION	BANDWIDTH MHz	INPUT CAPACITANCE	VOLTAGE MAX. DC + AC PK	READ OUT	CABLE LENGTH METERS
6551	X10	500	10 Pf	500	YES	1.2
6554	X10	500	10 Pf	500	NO	1.2
6552	ACCESSORY KIT					

### FEATURES:

- Small probe size is ideal for testing in hard to access areas.
- A set of accessories is included with each probe.
- As a minimum all probes meet IEC1010-2-031, 500 V CAT I, 300V CAT II.


### RATINGS:

Maximum voltage must be derated with respect to frequency.


**ORDERING INFORMATION:** Model 6551, 6552, 6554

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).  
All specifications are to the latest revisions. Specifications are subject to change without notice.  
Registered trademarks are the property of their respective companies. Made in USA


### OSCILLOSCOPE PROBE ACCESSORIES

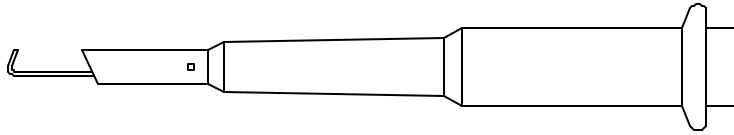


RETRACTABLE HOOK TIP

 


BNC ADAPTER

 

I.C. ADAPTER

 


INSULATING TIP

 


TRIMMER TOOL



 6" GROUND LEAD



SPRING

 

PROBE TIPS

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm .02$ " (.51 mm), .xxx =  $\pm .005$ " (.127 mm).  
All specifications are to the latest revisions. Specifications are subject to change without notice.  
Registered trademarks are the property of their respective companies. Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

6552 6550