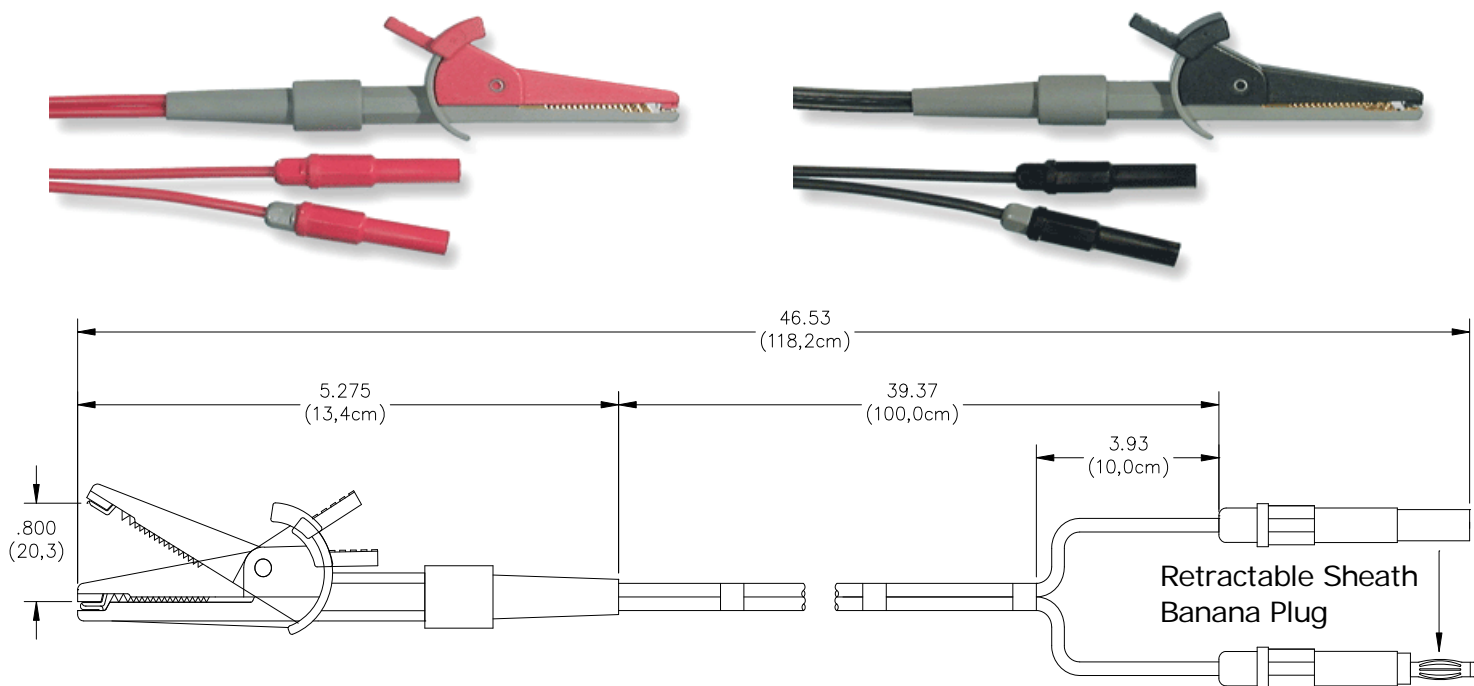


Model 6730
Wide Jaw Kelvin Lead Set**Features**

- True wire four wire lead set with gold plated alligator clips that open to a wide .800" (20.3mm).
- Long leads, over 46" (188 cm).
- Standard banana plugs with retractable sheath allows versatility in connecting to equipment.
- Color coded for easy source and sense identification.

Materials

Alligator Contacts:	Gold Plated Brass
Banana Plugs:	Nickel Plated Beryllium Copper
Spring:	Steel
Insulation:	Nylon 65, Nylon 6, Lucel, PVC
Wire:	Silicone

Ratings

Operating Voltage:	33 Vrms / 70 Vdc Max.
Current:	2A Max.
Temperature:	-10° to +55°C

Ordering Information

Model: 6730

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

6730