



## Model 72930

### Panel Mount IEC 61010 4mm (0.16in) Jack for Sheathed Plugs

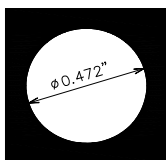

PANEL DRILLING  $\phi 0.472$ "

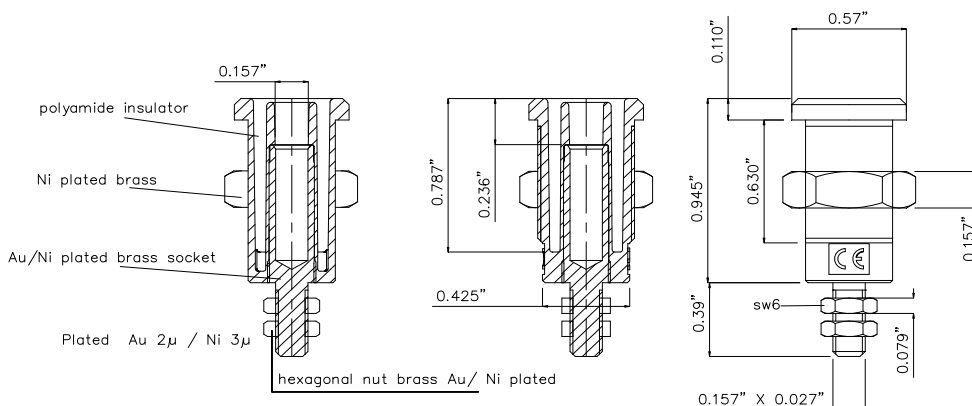

**Model 72930**  
**Panel Mount IEC 61010 4mm (0.16in) Jack for**  
**Sheathed Plugs**

## Materials

Body: Polyamide  
Hex Nut: Nickel-plated brass  
Stud: Nickel-plated brass  
Stud Hex Nuts: Nickel-plated brass

## Features

- Panel mount IEC61010 4mm (0.16in) banana jack for sheathed banana plugs, with threaded stud.
- Hexagonal nut.

## Specifications

<b>Max Current</b>	36A
<b>Max Voltage</b>	1000 V CAT III

M4 x 0.7 nut = Screwing Torque Nuts = 30 Ncm Max.

## Ordering Information

Model: 72930-\*

\*Available colors: 0=Black, 1=Brown, 2=Red, 4=Yellow, 5=Green, 6=Blue, 7=Violet, 8=Gray, 9=White

Ordering example: 72930-5 (72930 with Green Polyamide Insulation)

Each color sold in packages of 10 pieces.

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844  
**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500  
**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm 0.02$ " (.51 mm), .xxx =  $\pm 0.005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[72930-0](#) [72930-2](#) [72930-5](#) [72930-6](#) [72930-8](#) [72930-9](#) [72930-1](#) [72930-4](#) [72930-7](#)