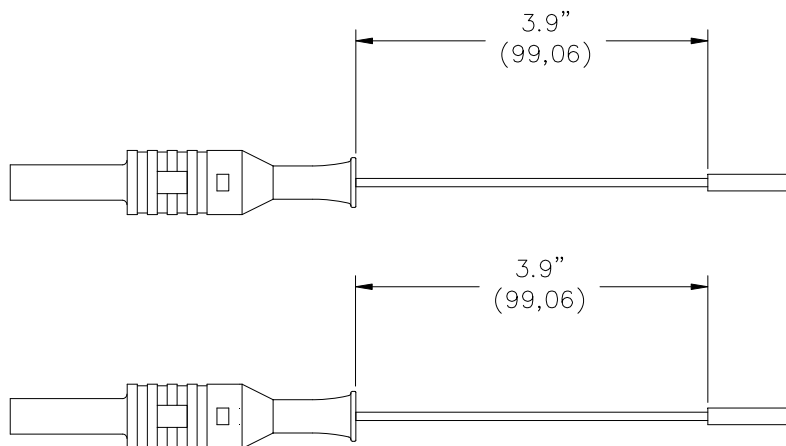


**Model 72936****2mm Sheathed Banana Plug to 4mm Sheathed Banana Plug****Features**

- Provides a quick and easy configuration between a 4mm sheathed banana jack to a 2mm sheathed banana jack.

**Materials**

2mm/4mm Banana Plugs:

*Body:* Nickel Plated Brass

*Spring:* Nickel Plated Beryllium Copper

Plug Insulation: Polypropylene, color per part number

Wire Insulation: PVC, color per part number

**Ratings**

Operating Voltage: For *CE Compliance* and for personal safety, do not hold in hand when voltages exceed 33 Vac/70 Vdc.

Do not use on circuits where transient stresses can exceed the rated voltage.

Operating Temperature: -20°C to +80°C (-4°F to +176°F) Max.

Operating Current: 2 Amperes Max.

**Ordering Information**

Model: 72936-XX-\*

XX = Standard Length: 39 (3.9in) (10cm)

\* = Standard Color: -0 Black, -2 Red

Ordering Example: 72936-39-2, Test Lead is 3.9in and Red.

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm .02$ " (.51 mm), .xxx =  $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[72936-39-0](#) [72936-39-2](#)