


Model 73046
N Type Jack to TNC Plug Adapter

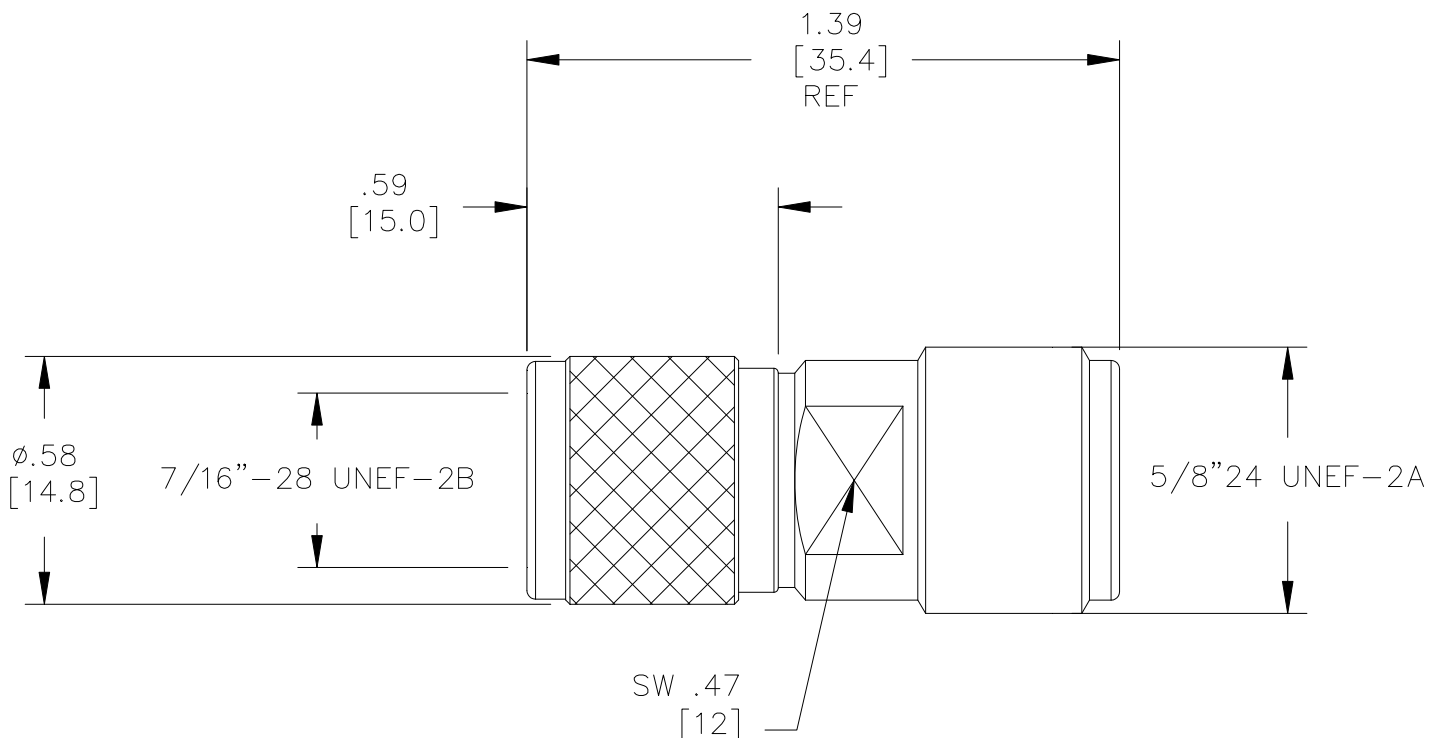

Model 73046
N Type Jack to TNC Plug Adapter

Materials

Center Conductor: Phosphor Bronze, Gold Plated
Connector Body: Brass, Nickel Plated
Insulators: PTFE

Specifications

Impedance: 50 Ω
Frequency Range: DC - 11GHz
Contact Resistance:
 Center Conductor: \leq 2.0 m Ω
 Outer Conductor: \leq 0.2 m Ω
Insulation Resistance: \geq 5000 M Ω
Dielectric Withstand Voltage: 1500V
 For CE compliance, do not hold in hand when
 voltages exceed 33 Vrms / 70 Vdc.
Number of Insertions: 500 cycles minimum

Ordering Information

Model: **73046**

Features

- DC - 11GHz bandwidth.
- Connectors are precision machined.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = \pm .02" (.51 mm), .xxx = \pm .005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[73046](#)