


Model 73082

SMA Quick-Connect Plug to SMA Plug, RG142B/U

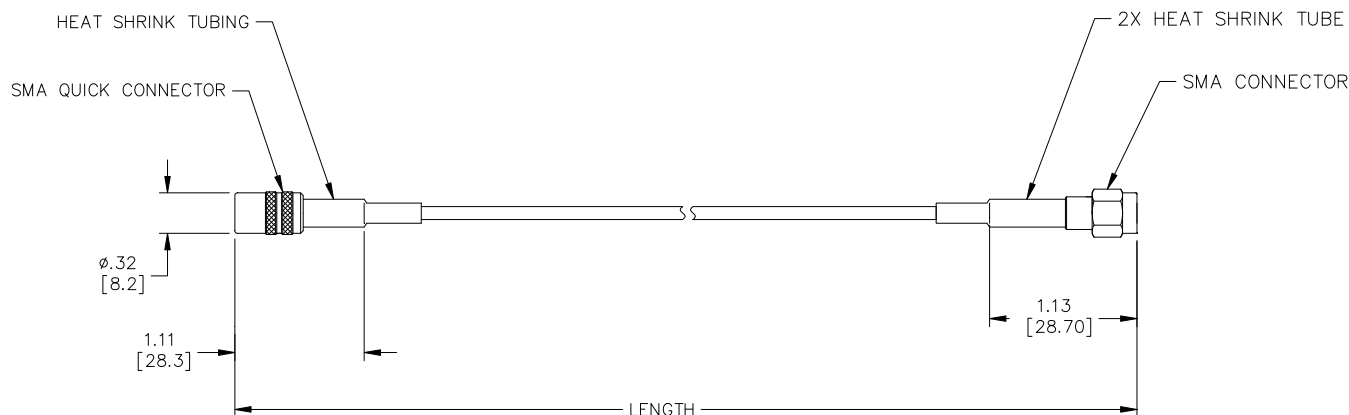

Model 73082
SMA Quick-Connect Plug to SMA Plug, RG142B/U

Small size, and durability for
confident connections

Materials

SMA Quick-Connect Male Connector:

Center Contact: Brass, Gold Plated
Connector Body: Brass, Nickel Plated
Crimp Ferrule: Copper, Nickel Plated
Insulators: PTFE

SMA Male Connector:

Center Contact: Brass, Gold Plated
Connector Body: Brass, Gold Plated
Crimp Ferrule: Copper, Nickel Plated
Insulators: PTFE

Features

- DC - 4GHz bandwidth.
- Precision machined connectors.
- Perfect for applications where space, weight, performance and ease of connection are required.

Specifications

Cable Type	RG142B/U
Impedance	50Ω
Frequency Range	DC - 4GHz
Insulation Resistance	≥ 1000 MΩ
Insulator Withstand	750V
Temperature Range	-65° C to +165°C (-85°F to +329°F)
Jacket	FEP
Cable O.D.	0.195" (4.95mm)
Center Conductor (mm)	.95 solid silver coated copper covered steel

Ordering Information

Model: **73082**

Cable Designator: **X** = RG142B/U

Standard Lengths: **12", 24", 36", 48", 60"**

- 12" ± .157" (305mm ± 4mm)
- 24" ± .275" (610mm ± 7mm)
- 36" ± .394" (914mm ± 10mm)
- 48" ± .512" (1219mm ± 13mm)
- 60" ± .630" (1524mm ± 16mm)

Ordering Example: **73082-X-36**, Cable is RG142B/U with length of 36" (914mm)

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[73082-X-12](#) [73082-X-48](#) [73082-X-60](#) [73082-X-24](#) [73082-X-36](#)