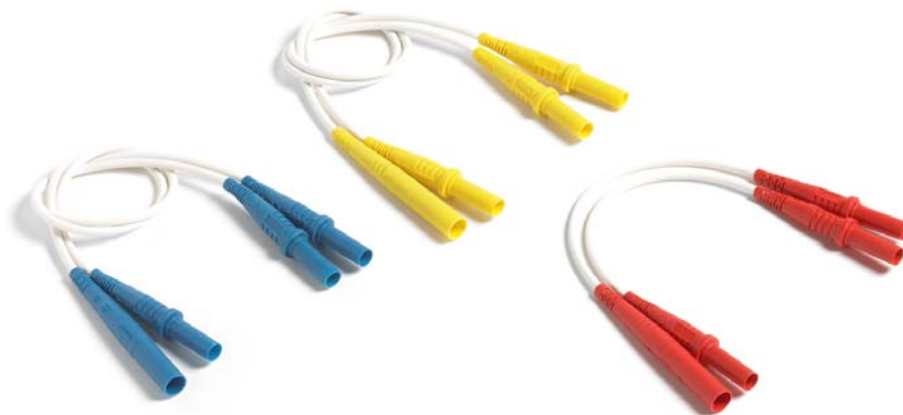


**Model 73087**  
**Jumper Test Lead Set**

**Model 73087, Jumper Test Lead Set**

## Features

- Each jumper test lead set includes one sheathed 4mm banana plug to sheathed 4mm banana plug test lead, and one sheathed 4mm banana plug to sheathed 4mm banana jack patch cord.
- Flexible jumper test lead sets are perfect for conducting *peer-checking system* tests with test point check before final connection.
- Perfect for use with the **73084**, **73085**, **73086**, and **73088** terminal jacks.
- Plug and housing are molded directly to the cable in an intergral one piece design and wire is double crimped for a long lasting connection.
- Multi-leaf banana spring is beryllium copper, nickel-plated for extended insertion cycle life and low contact resistance.
- High strand count silicone insulated wire offers excellent flexibility and high temperature resistance.
- *For more information, please visit our "Articles" section on nuclear applications at [www.pomonaelectronics.com](http://www.pomonaelectronics.com).*

## Materials

*Plug:* Brass, Nickel-plated

*Spring:* Beryllium Copper, Nickel plated

*Insulator:* Polypropylene

*Wire:* 18 AWG

*Wire Insulation:* Silicone, O.D. 0.146" (3.7mm)

## Ratings

Sheathed 4mm Banana Plug to Sheathed 4mm Banana Plug:

*Operating Temperature:* -4° to +131°F (-20° to +55°C)

*Operating Voltage:* CAT I, 1000 Vrms

*For hands free use only*

*Current:* 10 Amp Max

Sheathed 4mm Banana Plug to Sheathed 4mm Banana Jack:

*Operating Temperature:* -4° to +131°F (-20° to +55°C)

*Operating Voltage:* CAT I, 1000 Vrms

*For hands free use only*

*Current:* 10 Amp Max


**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

**Model 73087  
Jumper Test Lead Set**

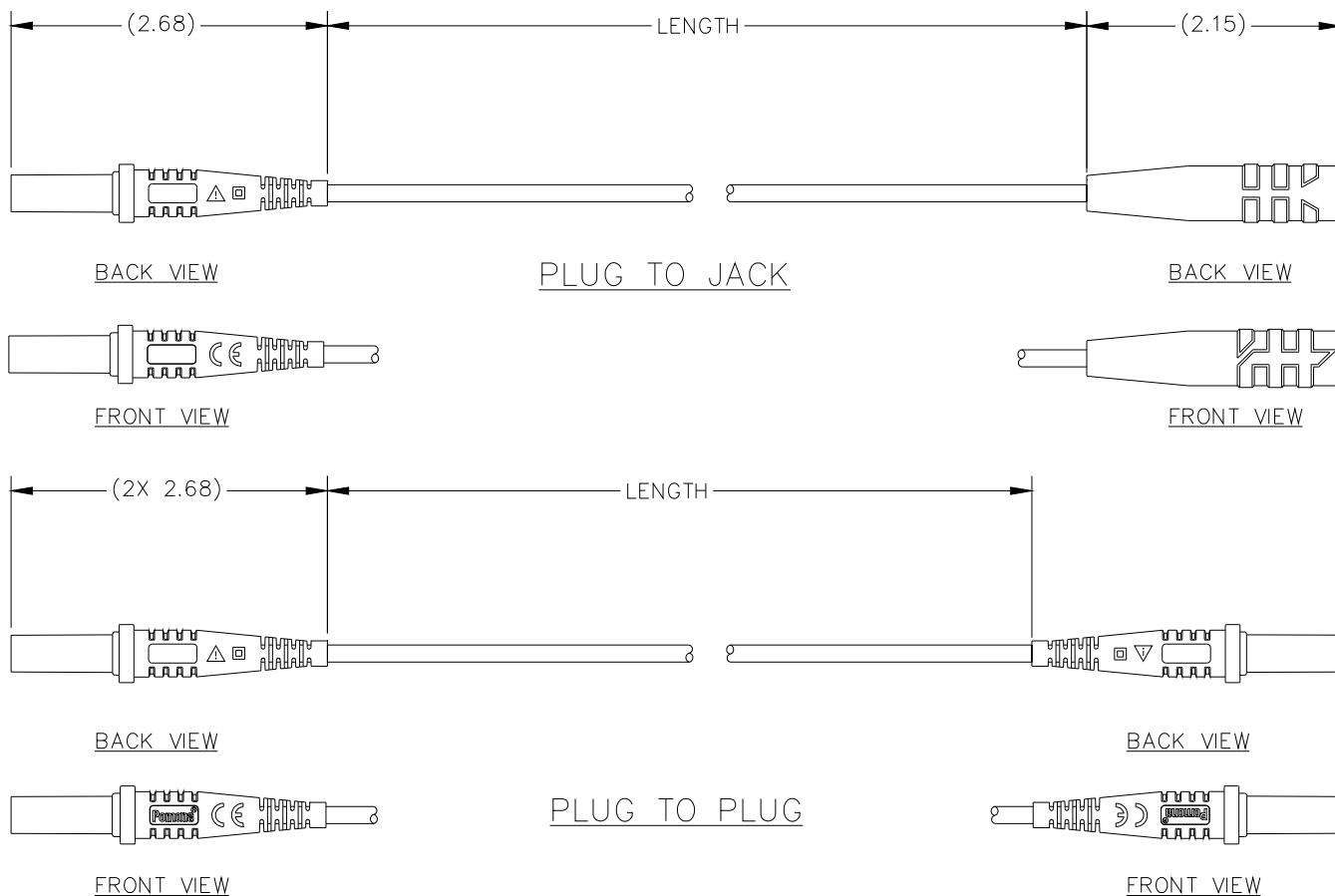

**Ordering Information**

Model: **73087-XX-\***

**XX = Standard Lengths: 6" (152), 12" (305), 24" (610), 36" (914), 72" (1829)**  
**(9" (229), 20" (508), 150" (3810), and 210" (5334) lengths available in blue only)**

Additional lengths may be quoted upon request.

\* = Colors: -0 Black, -2 Red, -4 Yellow, -6 Blue

Ordering Example: **73087-12-6**, banana plugs and jacks are Blue with a cable length of 12" (305mm)

**USA:** Sales: 800-490-2361  
 Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
 Fax: 425-446-5844  
**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500  
**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Pomona:

[73087-12-6](#) [73087-72-6](#) [73087-72-4](#) [73087-72-2](#) [73087-12-4](#) [73087-6-0](#) [73087-72-0](#) [73087-12-2](#) [73087-210-4](#)  
[73087-6-4](#) [73087-9-4](#) [73087-36-6](#) [73087-6-6](#) [73087-6-2](#) [73087-36-4](#) [73087-24-2](#) [73087-36-2](#) [73087-24-6](#) [73087-24-0](#) [73087-12-0](#) [73087-20-4](#) [73087-24-4](#) [73087-150-4](#) [73087-36-0](#)