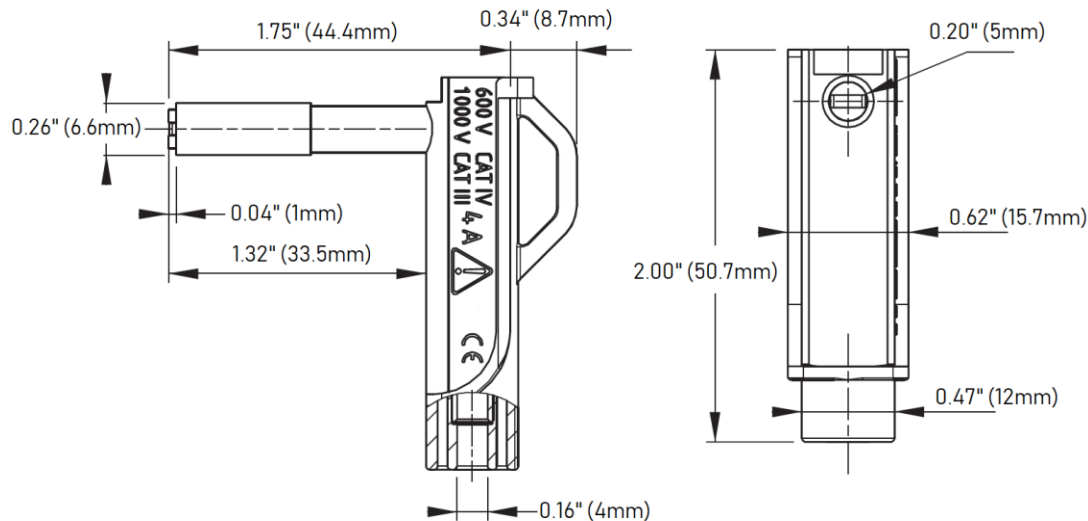


Model 73106
Right-Angle Magnetic Probe with 4mm Safety Jack**Features**

- Ideal for temporary connections to terminal blocks with metal screws
- Quick connect and disconnect with magnetic probe head
- Insulated 4mm safety banana jack for attachment to sheathed test leads
- Magnetic probe head diameter of 6.6mm (0.260")
- Compatible with popular Pomona test lead models 5907A, 5908A, and 5909A test lead sets

Materials

Conductor: Nickel-plated Brass and Magnetic Material

Insulation: Polypropylene

Ratings

Voltage: CAT II 1000V / CAT III 1000V / CAT IV 600V

Current: 4 amperes

Operating Temperature: +5°C to +40°C (+41°F to 104°F)

Ordering Information

Model: 73106-*color*

Color: 0=Black, 2=Red, 6=Blue

Right-Angle Magnetic Probe with 4mm Safety Jack



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[73106-0](#) [73106-2](#) [73106-6](#)