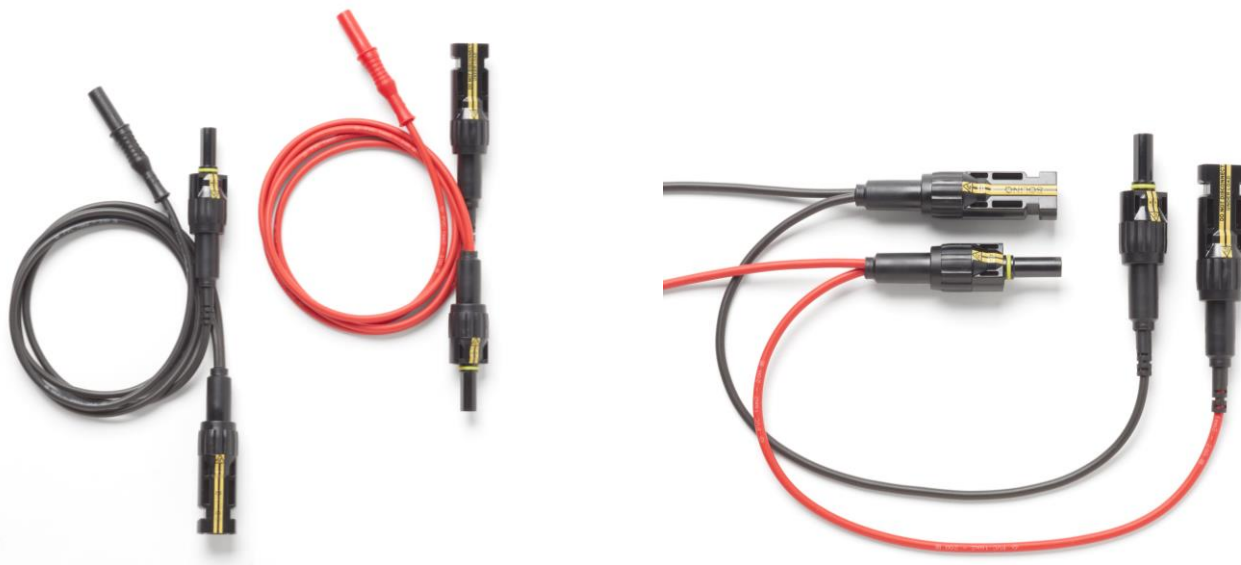


Model PVLEAD3
MC4 Solar Clamp Test Lead Set**Features**

- Set of black and red MC4 Solar Power Clamp Test Leads
- The black test lead is a MC4 (male) breakout to 12-inch MC4 (female) and 36-inch 4mm sheathed banana plug test lead
- The red test lead is a MC4 (female) breakout to 12-inch MC4 (male) and 36-inch 4mm sheathed banana plug test lead
- Designed for use with Solar Clamp Meters that accept 4mm sheathed banana plugs
- Creates connection between the Solar Panel and Inverter for measuring with a Clamp Meter
- Ensures safe DC power measurements on Photovoltaic (PV) modules and systems
- Allows user to monitor solar PV circuits during operation for troubleshooting and maintenance of PV systems
- Nickel plated contacts

Ratings

Voltage: Complies to IEC / EN 61010-031
CAT III 1000V / CAT IV 600V
Do Not Disconnect Under Load

Current: 20A

Temperature Range: +5°C to +40°C (+41°F to +104°F)

Ordering Information

Model: PVLEAD3
MC4 SOLAR POWER CLAMP SET

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[PVLEAD3](#)