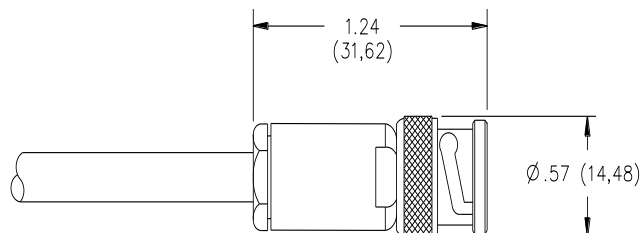


Model 5056 & Assembly Instructions
Triaxial Male 2 Lug Connector to Cable

Model 5056
Triaxial Male 2 Lug Connector to Cable

Features

- Fits Belden 9222 triaxial cable, 0.242" O.D.

Materials

Body and Fittings:	Brass, Tarnish Resistant Plating
Center Contacts:	Male: Brass, Gold Plated
Outer Contact:	Beryllium Copper, Gold Plated
Dielectric:	PTFE

Specifications

Voltage:	500 Vrms
Impedance:	50 Ohm
Temperature:	-65° C. (-85° F.) to +165° C. (+329° F.)
Frequency Range:	DC to 500 MHz

Ordering Information

Model: 5056
Triaxial Male 2 Lug Connector for Belden 9222 Cable

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Model 5056 & Assembly Instructions Triaxial Male 2 Lug Connector to Cable

 
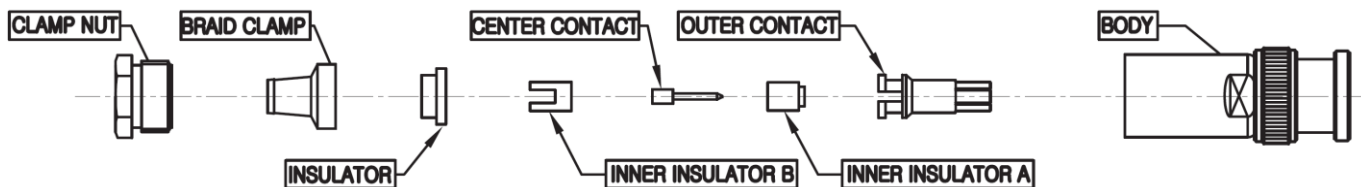


FIGURE #1

- 1.1 Strip cable per drawing lengths (mm).
- 1.2 Slide nut onto stripped cable.
- 1.3 Insert braid clamp and insulation on stripped cable.



FIGURE #2

- 2.1 Solder pin with center conductor then insert inner insulator A and B on the pin.
- 2.2 Peel back shield and insert outer contact.

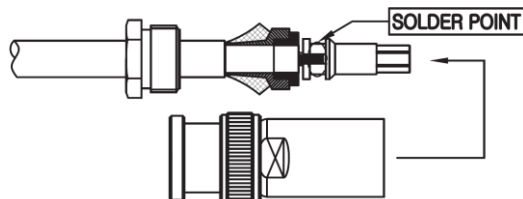


FIGURE #3

- 3.1 Position shield on solder point and solder outer contact to shield.
- 3.2 Insert body on assembled cable and fasten with wrench.

 


FIGURE #4

- 4.1 Completed assembly shown.

USA: Sales: 800-490-2361
 Technical Support: technicalsupport@pomonatest.com
 Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm),
 .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions.
 Specifications are subject to change without notice. Registered trademarks are
 the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[5056](#)