


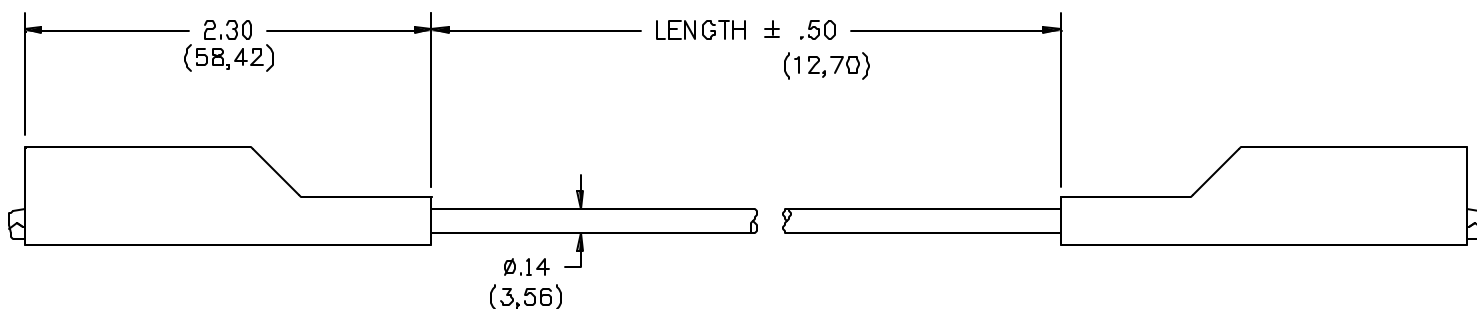

FEATURES:

- Ideal for use as a temporary jumper wire.
- Alligator jaws open to 0.30"

MATERIALS:

Wire: 18AWG, stranding 65x36 t.c., PVC insulated (.144) O.D.

Marking: "POMONA AL-B-XX"

Color: See ordering information

Connection: Insulated Alligator Clip

Material: Steel.

Finish Nickel plated.

Insulation: Vinyl. Color matches color of wire.

RATINGS:

Operating Temperature: +50° C (+122° F.) Max.

Voltage: Hand-held testing: 30VAC/60VDC Max.

Hands free testing in controlled voltage environments: 150 WVDC Max.

Current: 5 Amperes

ORDERING INFORMATION: Model AL-B-XX-*

*Std. Colors: Available in 10 colors

XX = Wire length, Standard length: See Table Below

*= Color, -0 Black, -1 Brown, -2 Red, -3 Orange, -4 Yellow, -5 Green, -6 Blue, -7 Violet, -8 Gray, -9 White

Lengths other than those specified are available on request.

Ordering example: AL-B-24-2 (Indicates 24 inches in Red).

Model 6356 Kit contains 10 patch cords, one each of 10 colors.

Model Number (Specify Color) *	XX=Length in Inches
AL-B-XX-*	4, 8, 12, 18, 24, 36, 48, 60, 72, 96

All dimensions are in inches and metric. All specifications are to the latest revisions. Specifications are subject to change without notice.
Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[AL-B-72-5](#) [AL-B-72-3](#) [AL-B-72-9](#) [AL-B-4-7](#) [AL-B-4-8](#) [AL-B-4-9](#) [AL-B-4-6](#) [AL-B-4-5](#) [AL-B-4-4](#) [AL-B-4-0](#) [AL-B-8-5](#)
[AL-B-8-2](#) [AL-B-8-6](#) [AL-B-8-0](#) [AL-B-8-4](#) [AL-B-36-6](#) [AL-B-36-3](#) [AL-B-36-9](#) [AL-B-36-4](#) [AL-B-36-5](#) [AL-B-12-9](#) [AL-B-](#)
[12-5](#) [AL-B-12-3](#) [AL-B-12-4](#) [AL-B-12-1](#) [AL-B-12-6](#) [AL-B-60-4](#) [AL-B-60-9](#) [AL-B-60-1](#) [AL-B-60-8](#) [AL-B-60-5](#) [AL-B-60-](#)
[6](#) [AL-B-60-7](#) [AL-B-18-3](#) [AL-B-18-6](#) [AL-B-18-1](#) [AL-B-18-7](#) [AL-B-18-0](#) [AL-B-18-9](#) [AL-B-18-5](#) [AL-B-18-4](#) [AL-B-18-8](#)
[AL-B-24-9](#) [AL-B-24-7](#) [AL-B-24-1](#) [AL-B-24-6](#) [AL-B-24-5](#) [AL-B-24-4](#) [AL-B-24-3](#) [6356-48](#) [AL-B-48-4](#) [AL-B-48-1](#) [AL-B-](#)
[48-6](#) [AL-B-48-7](#) [AL-B-48-9](#) [AL-B-48-5](#) [AL-B-24-02](#) [AL-B-48-3](#) [AL-B-48-8](#) [AL-B-12-7](#) [AL-B-12-8](#) [AL-B-24-8](#) [AL-B-](#)
[36-7](#) [AL-B-36-8](#) [AL-B-4-1](#) [AL-B-4-3](#) [AL-B-72-0](#) [AL-B-72-1](#) [AL-B-72-2](#) [AL-B-72-4](#) [AL-B-72-6](#) [AL-B-72-7](#) [AL-B-72-8](#)
[AL-B-8-1](#) [AL-B-8-3](#) [AL-B-8-7](#) [AL-B-8-8](#) [AL-B-8-9](#)