

Model PM2

**Meterman 38XR DMM, Data logging
Software and Pomona Deluxe Test lead Kit**

38XR Meterman DMM




Features: For designing and troubleshooting electronics, industrial automation and control systems, the 38XR deliver the highest safety rating available – CAT IV 600 V and CAT III 1000 V. The features include temperature, capacitance, frequency, 4-20mA loop current percentage, backlight and PC interface. With the addition of 38SW software and RS232 cable, the 38XR can be used for real-time data acquisition using any industry standard Windows® PC.

- ✓ 10,000-count with high 0.25 % accuracy
- ✓ Bright blue backlight for dim environments
- ✓ Duty cycle, capacitance and frequency
- ✓ 4-20 mA loop current with % readout
- ✓ Temperature to 2372 °F/1300 °C type K thermocouple included
- ✓ True rms AC + DC coupled for accurate ripple measurements
- ✓ 38XR includes heavy-duty test leads, threaded alligator clips, temperature adapter, type K thermocouple, manual, spare fuse and 9 V battery and Magne-Grip™ holster with magnetic hanging strap frees both hands for work
- ✓ Three-year warranty

38SW Meterman Software

Features:

- ✓ Real-time data acquisition software logs and displays data from all 38XR measurement functions
- ✓ Stores data for retrieval or for further analysis
- ✓ Exports data for use in Excel® or other programs
- ✓ Supports Windows® 98, NT, XP
- ✓ 38SW includes isolated optical interface cable

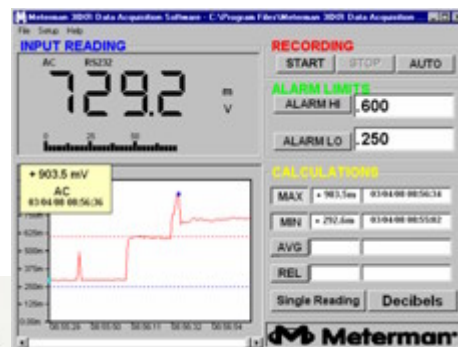

Visit www.metermantesttools.com for complete Meterman specifications.

Sales: 800-490-2361 Fax: 888-403-3360 Technical Assistance: 800-241-2060
For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com


Pomona 5904 Deluxe Test Lead Kit

Features:

- ✓ Probes, Alligators and Grabbers are modular for maximum connection versatility.
- ✓ High wire strand count with silicone insulation allows test leads to have superb flexibility.
- ✓ Components complies with International Safety Standard CAT III, IEC 1010-2-031.
- ✓ Right angle banana plug on test leads is ideal for hand held DMM.




Model **6232**: Test Probes

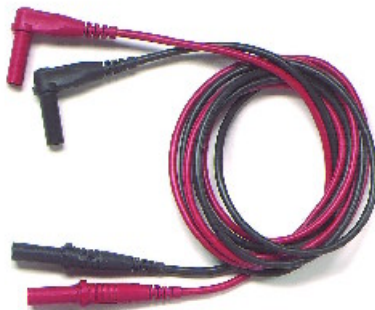

Model **5907A**: Straight to
Right Angle Banana Plug
Test Leads



Model **5912A**: Alligator Clip
Maxigrabbers

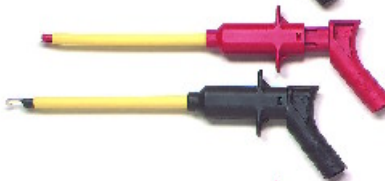

Model **5911A**: Hook Tip
Maxigrabbers



Model **5910A**: Pincer Tip
Maxigrabbers



Model **6041A**: Ex-Large
Alligator Clips



Model **5955**: Ttri-fold nylon pouch

Visit www.pomonaelectronics.com for complete specifications on individual Pomona models.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

PM2