

**Models 6854**  
**XLR (F) 5-pin Rectangular Flanged Panel Mount**



Model 6854 XLR (F) 5-pin rectangular flanged mount

Protect contacts and absorb vibrations in your audio applications.

**Features**


- 3-pin XLR panel mount with sturdy all metal one piece design.
- Solder cup terminations.
- Low contact resistance.
- Front mountable.

**Materials**

- Housing is die cast zinc alloy with tarnish resistant nickel plating.
- Contacts are bronze with tin finish (Ground tab is steel).

**Ordering Information**

Model: 6854.

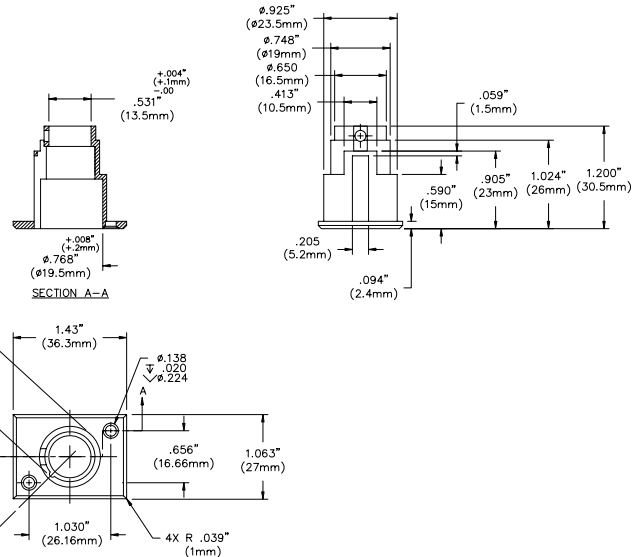

**Specifications**

Number of contacts	5
Contact resistance	< 5 m $\Omega$
Dielectric strength	1500 V dc
Wire size (AWG)	18 AWG (2.0 mm <sup>2</sup> ) max.

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 International: 425-446-5500

e-mail: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)

Where to Buy: [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm .02$ " (.51 mm), .xxx =  $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[6854](#)