
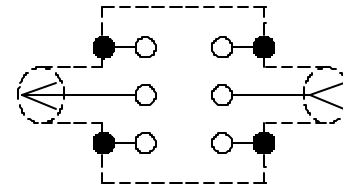
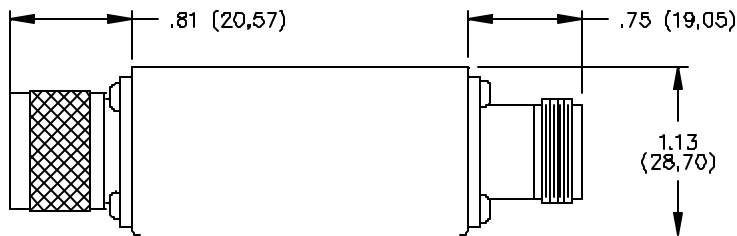
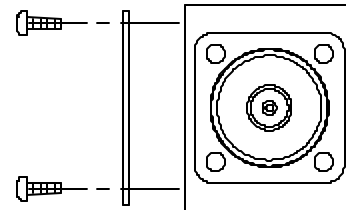


Model 2411 Size B Aluminum Box With Cover Type N Male To Female

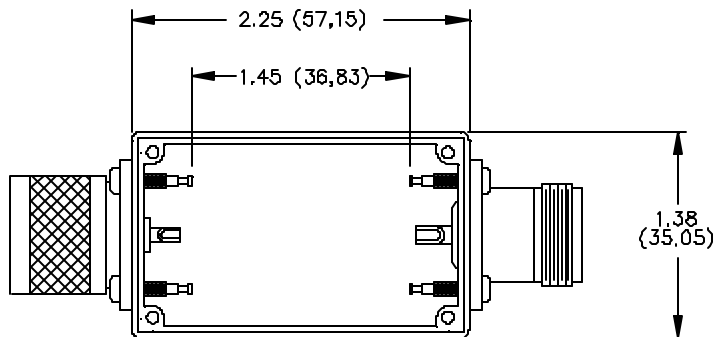

MATERIALS:

Connector: Type "N" Male & Type "N" Female

Body: Tarnish Resistant Plating, Center Contact: Male – Gold Plated Brass, Female – Gold Plated Beryllium Copper

Solder Turret Terminal Screws: Steel

Shielded Housing: Die cast aluminum alloy 380 or 384.

Finish: Blue baked enamel per Fed. Std. 595 25109 over primer wash

Cover: 1.02 (.040) thick aluminum #1100-H14

Finish: Clear anodized

Screws: 4 each #2-32 x (1/4"). Pan head self-tapping. Steel.

Finish: Blue zinc plated.

Marking "Pomona 2411"

RATINGS:

Operating Voltage: Inner conductor/Shield: 1000 VRMS Max.

Operating Temperature: -55°C to +150°C

Nominal Impedance: 50 Ohms

ORDERING INFORMATION: Model 2411

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[2411](#)