


## Model 2952 Adapter – Standard Double Banana Jack To Miniature Double Banana Plug

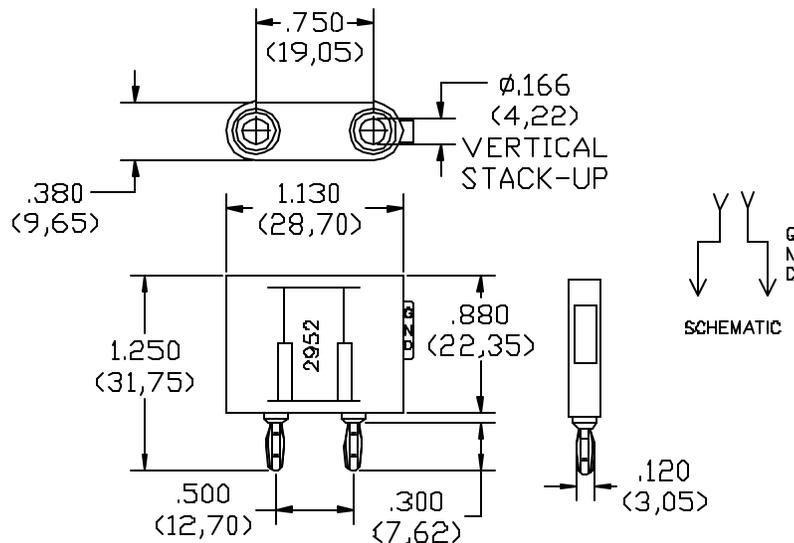

### FEATURES:

- Permits Standard Double Banana Plug on 19.1 (.750) centers to be used with equipment having Miniature Double Jacks on 12.7 (.500) centers.

### MATERIALS:

Upper Conn: Standard Double Banana Jack

Material: Brass per QQ-B-626, Alloy 360, ½ Hard.

Finish: Nickel plate per QQ-N-290, Class 2, (.00002/.0003).

Insulation: ABS molded to Banana Jacks and Banana Plug Bodies.

Color: Black.

Marking: "POMONA 2952."

Lower Conn: Miniature Double Banana Plug

Material: Spring – Beryllium Copper per QQ-C-533, Alloy 172, Cond. H.T.

Plug Body: Same as above.

Finish: Nickel plate per QQ-N-290.

### RATINGS:

Operating Temperature: +50° C (+122° F) Max.

Operating Voltage: 2500 VDC.

Current: 5 Amperes

### ORDERING INFORMATION: Model 2952

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Pomona:](#)

[2952](#)