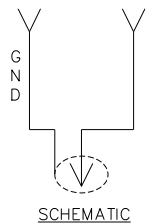
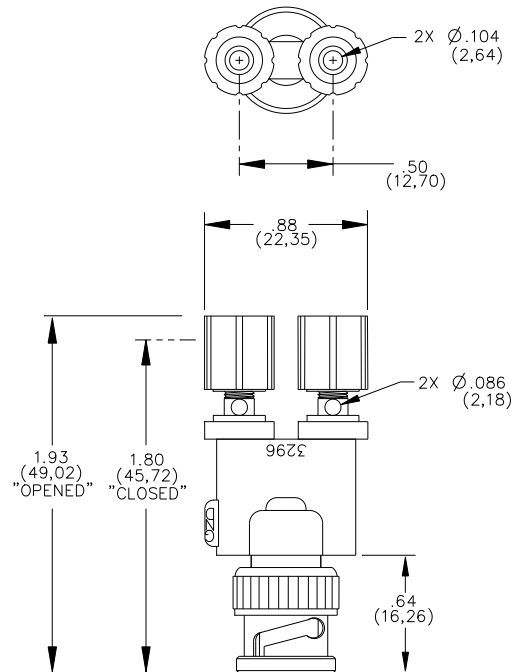


**Model 3296**  
**Adapter, Miniature Binding Posts to BNC Male****Features**

- Converts BNC female connection to Miniature Binding Posts and Miniature Banana Jacks

**Materials**

Body: Brass, Tarnish Resistant Plating

Center Contact: Gold Plated Brass

Marking: "3296"

**Ratings**

Operating Temperature: +50° C. (+122° F.) Max.

Operating Voltage: 500 Vrms, Maximum voltage for hands free use in controlled voltage environment.  
For CE compliance, do not hold in hand when voltages exceed 30V AC / 60V DC.

**Ordering Information**

Model 3296

**USA:** Sales: 800-490-2361  
Technical Support: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)  
Fax: 425-446-5844  
**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500  
**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm .02$ " (.51 mm), .xxx =  $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

3296