


## Model 72920 2mm SAFETY Sheathed Patch Cords

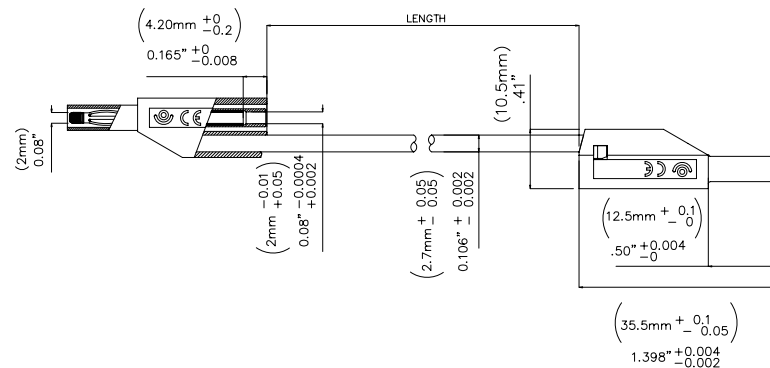

### Features

- Multi-stacking 2mm safety sheathed male/male patch cord, PVC
- Rating: 600V Cat II
- 10A Max.

### Materials

- Plug Body: Nickel Plated Brass
- Spring: Nickel plated Beryllium copper
- Spring tip: Polysulfone
- Insulation: Polypropylene.
- Wire Insulation: PVC.

### Ordering Information

Model: 72920-Length-Color  
Lengths: 20 inch (50cm) or 39in (100mm)  
Colors: Black (-0) or Red (-2)

### Specifications

Operating Temperature	-20 °C to +80 °C
Max Current	10A
Max Voltage	600 V CAT II
Max Resistance	15 m Ω at 20 inch 20 m Ω at 39 inch

**USA:** Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

**Europe:** 31-(0) 40 2675 150 **International:** 425-446-5500

**e-mail:** [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)

**Where to Buy:** [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[72920-39-2](#) [72920-20-0](#) [72920-20-2](#) [72920-39-0](#)