

L-Series - UL489 Miniature Molded Case Circuit Breaker - 1 pole C-Trip / DC




One Pole

Standard Pack: 12


Weight: 1.7kg (3.74 lb.)

Rated Current	Type/ Cat. No.
0.2A	DC1CU02L
0.5A	DC1CU05L
1.0A	DC1CU1L
1.6A	DC1CU1.6L
2.0A	DC1CU2L
3.0A	DC1CU3L
4.0A	DC1CU4L
5.0A	DC1CU5L
6.0A	DC1CU6L
8.0A	DC1CU8L
10A	DC1CU10L
12A	DC1CU12L
13A	DC1CU13L
15A	DC1CU15L
16A	DC1CU16L
20A	DC1CU20L
25A	DC1CU25L
30A	DC1CU30L
32A	DC1CU32L
40A	DC1CU40L
50A	DC1CU50L
60A	DC1CU60L
63A	DC1CU63L


DC Version Current/ Voltage Rating	0.2-63A/125/250VDC
Calibration Temperature	40°C (104°F)
Operating Temperature	-25° to 60°C (-13° to 140°F)
Storage Temperature	-25° to 75°C (-13° to 167°F)
Terminal Size Acceptability:	
Solid Wire	18 AWG -10 AWG
Stranded Wire	18 AWG -6 AWG
Terminal Torque	2.8 Nm (25 lb-in.)
Terminal Protection Degree	IP20
Electrical Life	6000 cycles on/off
Mechanical Life	100000 cycles on/off
Wire Connection	copper wire only 60/75°C

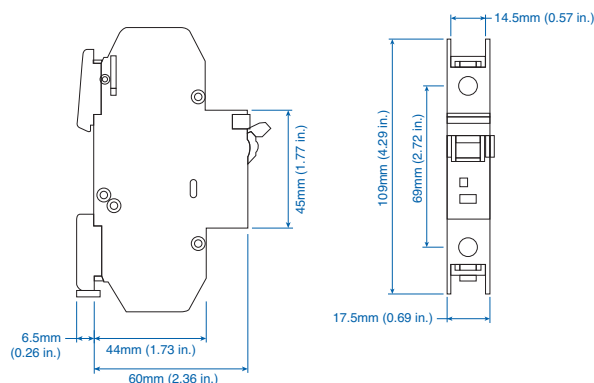

C and D Trip, Less than 10A

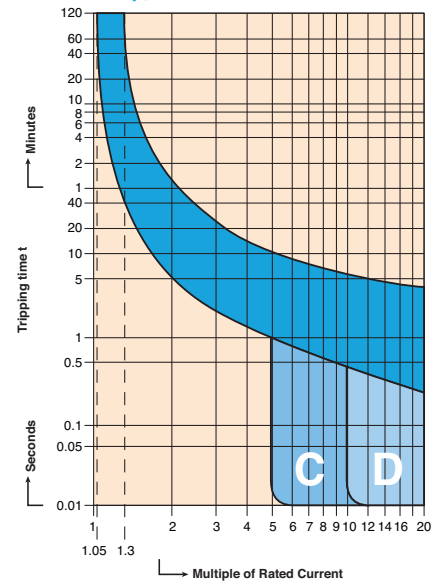

C and D Trip, 10A and higher

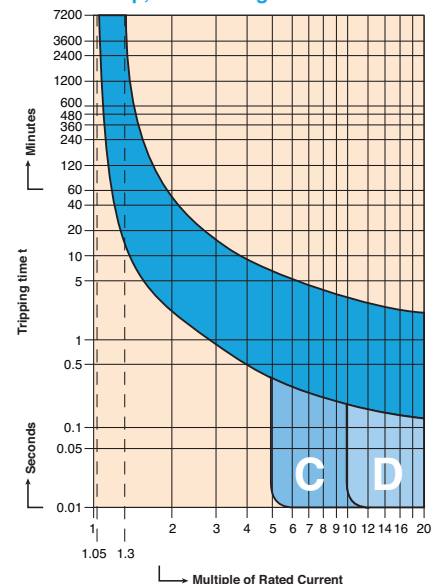

DC - SHORT CIRCUIT INTERRUPTING RATING

No. Poles	Type	0.2-32A
1	DC	10kA @ 125V



For ring tongue terminal version, replace "U" with "R" in part number. For example **DC1CR20L** instead of **DC1CU20L**.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[DC1CU15L](#) [DC1CU20L](#) [DC1CU40L](#) [DC1CU6L](#) [DC1CU12L](#) [DC2CU12L](#) [DC1DU12L](#) [DC1CU02L](#) [DC1CU10L](#)
[DC1CU5L](#) [DC1CU25L](#) [DC1CU30L](#) [DC1CU63L](#) [DC1CU05L](#) [DC1CU13L](#) [DC1CU8L](#) [DC1CU4L](#) [DC1CU3L](#)
[DC1CU2L](#) [DC1CU32L](#) [DC1CU50L](#) [DC1CU60L](#) [DC1CU1L](#) [DC1CU16L](#) [DC1CU1.6L](#) [DC1DU1.6L](#) [DC2CU1.6L](#)