

L-Series - UL489 Miniature Molded Case Circuit Breaker - 2 pole C-Trip / DC



LISTED
E305318



Two Pole


Standard Pack: 4

Weight: 1.7kg (3.74 lb.)



Rated Current	Type/ Cat. No.
0.2A	DC2CU02L
0.5A	DC2CU05L
1.0A	DC2CU1L
1.6A	DC2CU1.6L
2.0A	DC2CU2L
3.0A	DC2CU3L
4.0A	DC2CU4L
5.0A	DC2CU5L
6.0A	DC2CU6L
8.0A	DC2CU8L
10A	DC2CU10L
12A	DC2CU12L
13A	DC2CU13L
15A	DC2CU15L
16A	DC2CU16L
20A	DC2CU20L
25A	DC2CU25L
30A	DC2CU30L
32A	DC2CU32L
40A	DC2CU40L
50A	DC2CU50L
60A	DC2CU60L
63A	DC2CU63L

DC Version Current/ Voltage Rating	0.2-63A/125/250VDC
Calibration Temperature	40°C (104°F)
Operating Temperature	-25° to 60°C (-13° to 140°F)
Storage Temperature	-25° to 75°C (-13° to 167°F)
Terminal Size Acceptability:	
Solid Wire	18 AWG -10 AWG
Stranded Wire	18 AWG -6 AWG
Terminal Torque	2.8 Nm (25 lb-in.)
Terminal Protection Degree	IP20
Electrical Life	6000 cycles on/off
Mechanical Life	100000 cycles on/off
Wire Connection	copper wire only 60/75°C

C and D Trip, Less than 10A

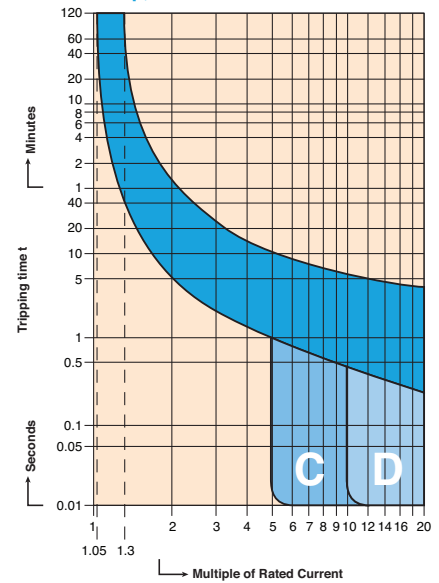

C and D Trip, 10A and higher

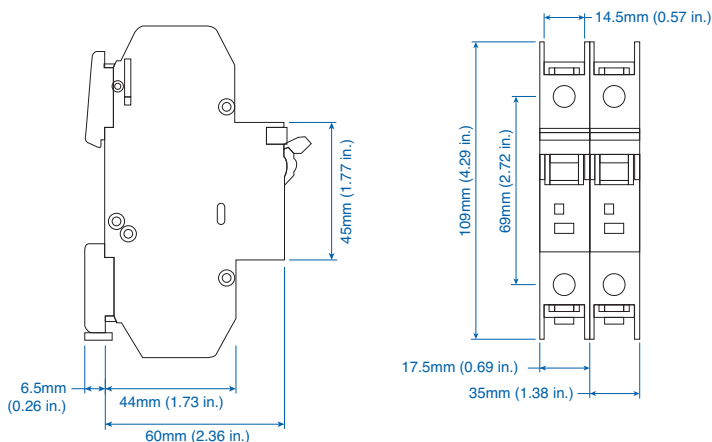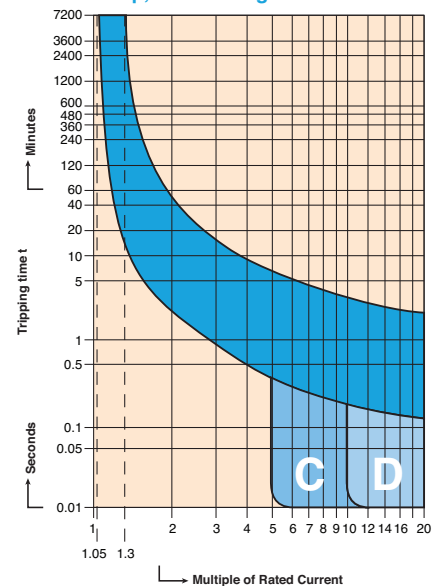

For ring tongue terminal version, replace "U" with "R" in part number. For example **1CR20L** instead of **1CU20L**.

DC - SHORT CIRCUIT INTERRUPTING RATING

No. Poles	Type	0.2-32A	33-63A
1	DC	10kA @ 125V	10kA @ 125V
2	DC	10kA @ 250V	10kA @ 250V

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[DC2CU5L](#) [DC2CU3L](#) [DC2CU30L](#) [DC2CU4L](#) [DC2CU15L](#) [DC2CU10L](#) [DC2CU25L](#) [DC2CU13L](#) [DC2CU02L](#)
[DC2CU32L](#) [DC2CU05L](#) [DC2CU1L](#) [DC2CU60L](#) [DC2CU40L](#) [DC2CU6L](#) [DC2CU50L](#) [DC2CU2L](#) [DC2CU63L](#)
[DC2CU20L](#) [DC2CU8L](#) [DC2CU16L](#)