


## Cat No. 733-714

### AK-F 14 Plus

#### Description

Distribution box - Industrial Quality -, flange type, with open top and bottom, for use with various flanges or to combine multiple AK-F - distribution boxes with combination flange, 1 row, 14 modules with pre-installed height adjustable DIN rail. Integrated ventilation elements included to reduce condensation. Labeling strips included. Additional connection space has standard 35 mm DIN rail installed.

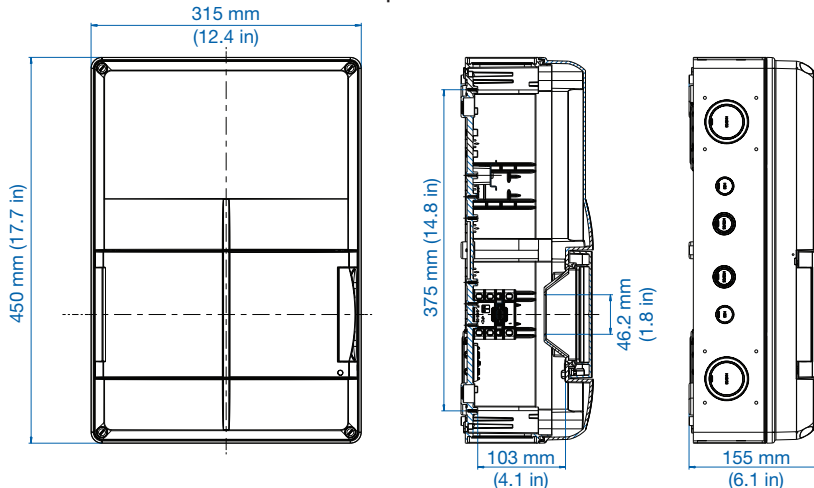

#### Knockouts on each side:

2 x M40/50  
2 x M20/25  
2 x M20

#### Rear Knockouts:

2 x M32/40  
6 x M20/25



315 x 450 x 155 mm  
(12.4 x 17.7 x 6.1 in)

UL US E254144 UL TYPE 3R, 12, 12K  
UL EU  
D'E  
CE  
PROTECTION IP65


Flange end walls sold separately see page 33.

## Cat No. 733-728

### AK-F 28 Plus

#### Description

Distribution box - Industrial Quality -, flange type, with open top and bottom, for use with various flanges or to combine multiple AK-F - distribution boxes with combination flange, 2 rows, 28 modules with pre-installed height adjustable DIN rail. Integrated ventilation elements included to reduce condensation. Labeling strips included. Additional connection space has standard 35 mm DIN rail installed.

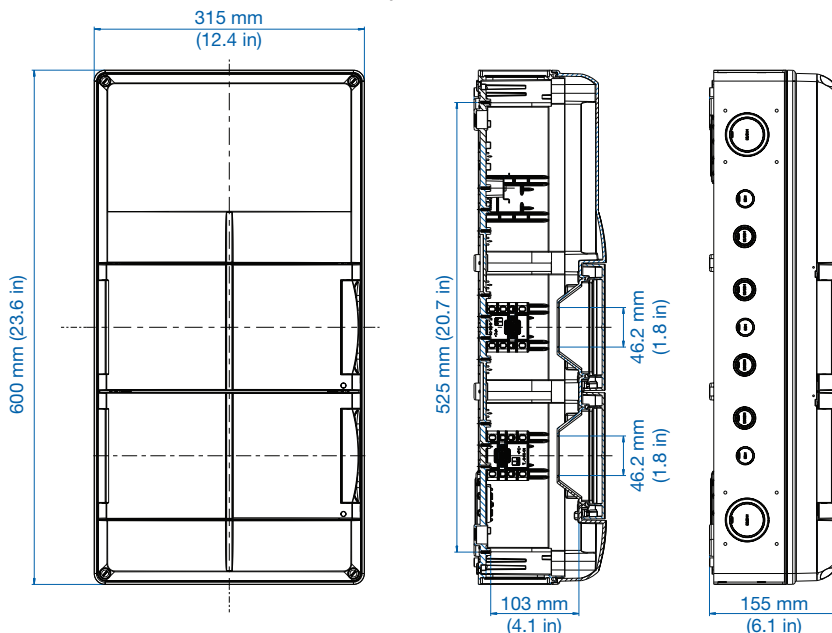

#### Knockouts on each side:

2 x M40/50  
4 x M20/25  
3 x M20

#### Rear Knockouts:

2 x M32/40  
8 x M20/25



315 x 600 x 155 mm  
(12.4 x 23.6 x 6.1 in)

UL US E254144 UL TYPE 3R, 12, 12K  
UL EU  
D'E  
CE  
PROTECTION IP65

Flange end walls sold separately see page 33.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[733-714](#)