 



MULTIPLE CONNECTION TERMINAL BLOCKS

CP SERIES


PUSH-IN TECHNOLOGY

CP1.5/3

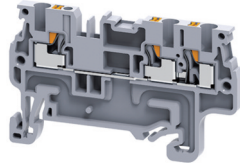


3 Connection Feed-Through
2 Jumper Channels

CP1.5/4

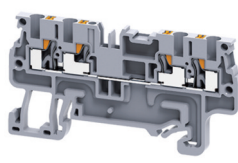


4 Connection Feed-Through
2 Jumper Channels

CP2.5/3

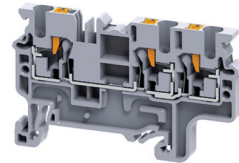

3 Connection Feed-Through
2 Jumper Channels

CP2.5/4

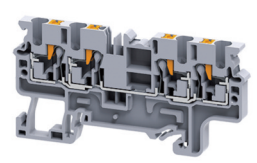

4 Connection Feed-Through
2 Jumper Channels

Dimensions & Weight

Width / Length	3.5 mm / 54.5 mm	3.5 mm / 63.5 mm	5 mm / 62.5 mm	5 mm / 73 mm
Height w DIN Rail 35 x 7.5 mm 35 x 15 mm	32.8 mm 40.3 mm	32.8 mm 40.3 mm	38.3 mm 45.8 mm	38.3 mm 45.8 mm
Weight per piece	4.2 g	4.8 g	6.8 g	8.6 g

Technical Data/Ratings

Approvals



Wire Size (solid / stranded)	24-14 AWG	0.2-1.5 mm ²	24-14 AWG	0.2-1.5 mm ²	24-12 AWG	0.2-2.5 mm ²	24-12 AWG	0.2-2.5 mm ²
Voltage Rating	600 V	800V AC/DC	600 V	800V AC/DC	600 V	1000V AC/DC	600 V	1000V AC/DC
Current Rating	15 A	15 A	15 A	15 A	20 A	24 A	20 A	24 A

Insulation Material	Polyamide 66	Polyamide 66	Polyamide 66	Polyamide 66
---------------------	--------------	--------------	--------------	--------------

Installation Instructions

Wire Stripping Length	8 mm	8 mm	10 mm	10 mm
Screwdriver	SCM0.4/2.5 (0.4 x 2.5 mm blade)	SCM0.4/2.5 (0.4 x 2.5 mm blade)	SCM0.5/3.0 (0.5 x 3.0 mm blade)	SCM0.5/3.0 (0.5 x 3.0 mm blade)

Terminal Blocks	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Grey (standard)	CP1.5/3	100	CP1.5/4	100	CP2.5/3	100	CP2.5/4	100
Red R	CP1.5/3/R	100	CP1.5/4/R	100	CP2.5/3/R	100	CP2.5/4/R	100
Blue BU	CP1.5/3/BU	100	CP1.5/4/BU	100	CP2.5/3/BU	100	CP2.5/4/BU	100
Black BL	CP1.5/3/BL	100	CP1.5/4/BL	100	CP2.5/3/BL	100	CP2.5/4/BL	100
Orange O	CP1.5/3/O	100	CP1.5/4/O	100	CP2.5/3/O	100	CP2.5/4/O	100
Green G	CP1.5/3/G	100	CP1.5/4/G	100	CP2.5/3/G	100	CP2.5/4/G	100
Yellow Y	CP1.5/3/Y	100	CP1.5/4/Y	100	CP2.5/3/Y	100	CP2.5/4/Y	100
White W	CP1.5/3/W	100	CP1.5/4/W	100	CP2.5/3/W	100	CP2.5/4/W	100
Ground/ Earth								
Yellow / Green	CPG1.5/3	100	CPG1.5/4	100	CPG2.5/3	100	CPG2.5/4	100

Jumpers	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.
Pluggable Jumpers												
2 pole	JX1.5/2	16A	100	JX1.5/2	16A	100	JX2.5/2	24A	100	JX2.5/2	24A	100
3 pole	JX1.5/3	16A	50	JX1.5/3	16A	50	JX2.5/3	24A	50	JX2.5/3	24A	50
4 pole	JX1.5/4	16A	50	JX1.5/4	16A	50	JX2.5/4	24A	50	JX2.5/4	24A	50
5 pole	—	—	—	—	—	—	JX2.5/5	24A	50	JX2.5/5	24A	50
6 pole	—	—	—	—	—	—	JX2.5/6	24A	10	JX2.5/6	24A	10
7 pole	—	—	—	—	—	—	JX2.5/7	24A	10	JX2.5/7	24A	10
8 pole	—	—	—	—	—	—	JX2.5/8	24A	10	JX2.5/8	24A	10
10 pole	JX1.5/10	16A	10	JX1.5/10	16A	10	JX2.5/10	24A	10	JX2.5/10	24A	10
16 pole	—	—	—	—	—	—	—	—	—	—	—	—
Step Down Jumpers	—	—	—	—	—	—	JXS4/2.5	32A	50	JXS4/2.5	32A	50
—	—	—	—	—	—	—	JXS6/2.5	41A	50	JXS6/2.5	41A	50
—	—	—	—	—	—	—	—	—	—	—	—	—

Accessories	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
End Plate	EPCP1.5/3	50	EPCP1.5/4	50	EPCX2.5/3	50	EPCX2.5/4	50
Partition Plate	PPCX4/3	50	PPCX4/4	50	PPCX4/3	50	PPCX4/4	50
DIN Rail	2511120	20	2511120	20	2511120	20	2511120	20
	CA701-15/S	20	CA701-15/S	20	CA701-15/S	20	CA701-15/S	20
End Stop	CA103 / CA104	50	CA103 / CA104	50	CA103 / CA104	50	CA103 / CA104	50
Test Plug	—	—	—	—	TX2.5	20	TX2.5	20
Marking Tag	MS3.5	1 Pk. (100 tags)	MS3.5	1 Pk. (100 tags)	MT5	1 Pk. (100 tags)	MT5	1 Pk. (100 tags)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CP1.5/3](#) [CP1.5/3/BL](#) [CP1.5/3/BU](#) [CP1.5/3/G](#) [CP1.5/3/O](#) [CP1.5/3/R](#) [CP1.5/3/W](#) [CP1.5/3/Y](#) [CP1.5/3/DB](#)