 

 
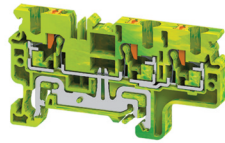


CPG4/3



 

3 Connection Ground Terminal
2 Jumper Channels

CPG4/4

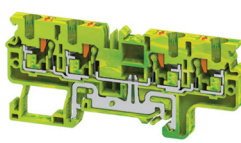

4 Connection Ground Terminal
2 Jumper Channels

CPG6/10/3

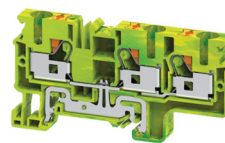

3 Connection Ground Terminal
2 Jumper Channels

Dimensions & Weight

Width / Length	6 mm / 70.5 mm	6 mm / 86.2 mm	8 mm / 82.9 mm
Height w DIN Rail	35 x 7.5 mm 35 x 15 mm	38.3 mm 45.8 mm	43.0 mm 50.6 mm
Weight per piece	12.4 g	14.4 g	24.8 g

Technical Data/Ratings

Approvals						
Wire Size (solid / stranded)	24-10 AWG	0.2-4.0 mm ²	24-10 AWG	0.2-4.0 mm ²	20-8 AWG	0.5-10.0 mm ²
Voltage Rating	600 V	1000V AC/DC	600 V	1000V AC/DC	600 V	1000V AC/DC
Current Rating	—	—	—	—	—	—

Insulation Material	Polyamide 66		Polyamide 66		Polyamide 66	
---------------------	--------------	--	--------------	--	--------------	--

Installation Instructions

Wire Stripping Length	11 mm		11 mm		12 mm	
Screwdriver	SCM0.5/3.0 (0.5 x 3.0 mm blade)		SCM0.5/3.0 (0.5 x 3.0 mm blade)		SCM0.8/4.0 (0.8 x 4.0 mm blade)	

Terminal Blocks	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Ground/ Earth Yellow / Green	CPG4/3	50	CPG4/4	50	CPG6/10/3	50

Jumpers		Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.
Shorting Link/ Jumpers	2 pole	JX4/2	32A	100	JX4/2	32A	100	JX6/2	41A	100
	3 pole	JX4/3	32A	50	JX4/3	32A	50	JX6/3	41A	50
	4 pole	JX4/4	32A	50	JX4/4	32A	50	JX6/4	41A	50
	5 pole	—	—	—	—	—	—	—	—	—
	6 pole	—	—	—	—	—	—	—	—	—
	7 pole	—	—	—	—	—	—	—	—	—
	8 pole	JX4/8	32A	10	JX4/8	32A	50	—	—	—
	10 pole	JX4/10	32A	10	JX4/10	32A	10	JX6/10	41A	10
	16 pole	JX4/16	32A	10	JX4/16	32A	10	—	—	—
Step Down Jumpers	4-2.5 mm ²	JXS4/2.5	32A	50	JXS4/2.5	32A	50	—	—	—
	6-2.5 mm ²	—	—	—	—	—	—	JXS6/2.5	41A	50
	6-4 mm ²	JXS6/4	41A	50	JXS6/4	41A	50	JXS6/4	21A	50

Accessories	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
End Plate	EPCX4/3	50	EPCX4/4	50	EPCX6/3	50
Partition Plate	PPCX4/3	50	PPCX4/4	50	—	—
DIN Rail	2511120 CA701-15/S	20 20	2511120 CA701-15/S	20 20	2511120 CA701-15/S	20 20
End Stop	CA103 / CA104	50	CA103 / CA104	50	CA103 / CA104	50
Test Plug	—	—	—	—	—	—
Marking Tag	MT6	1 Pk. (100 tags)	MT6	1 Pk. (100 tags)	MT8	1 Pk. (100 tags)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CPG4/4](#)