
 


CP3L2.5

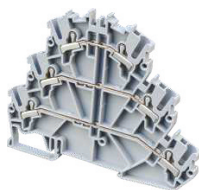

 

3 Level Terminal Block
Jumper Channel Each Level

CP3L2.5(I.S)





3 Level Terminal Block
Internally Shorted

CP3LG2.5

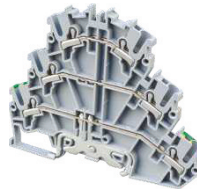

3 Level Terminal Block
Bottom Ground

 CP3LG2.5(I.S)

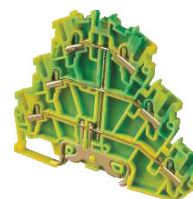

3 Level Terminal Block
6 Connections, Ground

Dimensions & Weight

Width / Length	5 mm / 98.70 mm	5 mm / 98.70 mm	5 mm / 98.70 mm	5 mm / 98.70 mm
Height w DIN Rail 35 x 7.5 mm 35 x 15 mm	83.10 mm 90.60 mm	83.10 mm 90.60 mm	83.10 mm 90.60 mm	83.10 mm 90.60 mm
Weight per piece	18.6 g	19.9 g	23.2 g	24.4 g

Technical Data/Ratings

Approvals								
Wire Size (solid / stranded)	22-12 AWG	0.34-2.5 mm ²	22-12 AWG	0.34-2.5 mm ²	22-12 AWG	0.34-2.5 mm ²	22-12 AWG	0.34-2.5 mm ²
Voltage Rating	300 V	500V	300 V	500V	300 V	500V	300 V	500V
Current Rating	20 A	24 A	20 A	24 A	20 A (Top 2 Levels)	24 A (Top 2 Levels)	-	-
Insulation Material	Polyamide 66		Polyamide 66		Polyamide 66		Polyamide 66	

Installation Instructions



Wire Stripping Length	10 mm	10 mm	10 mm	10 mm
Screwdriver	SCM0.5/3.0 (0.5 x 3.0 mm blade)	SCM0.5/3.0 (0.5 x 3.0 mm blade)	SCM0.5/3.0 (0.5 x 3.0 mm blade)	SCM0.5/3.0 (0.5 x 3.0 mm blade)

Terminal Blocks	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Grey (standard)	CP3L2.5	30	CP3L2.5(I.S)	30	-	-	-	-
Ground/ Earth	-	-	-	-	CP3LG2.5	30	CP3LG2.5(I.S)	30
Yellow / Green	-	-	-	-	-	-	-	-

Jumpers		Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.	Cat. No.	Imax	Std. Pk.
Shorting Link/ Jumpers	2 pole	CA801/A2	24A	100	CA801/A2	24A	100	CA801/A2	24A	100	CA801/A2	24A	100
	3 pole	CA801/A3	24A	100	CA801/A3	24A	100	CA801/A3	24A	100	CA801/A3	24A	100
	4 pole	CA801/A4	24A	100	CA801/A4	24A	100	CA801/A4	24A	100	CA801/A4	24A	100
	10 pole	CA801/A10	24A	10	CA801/A10	24A	10	CA801/A10	24A	10	CA801/A10	24A	10

Accessories	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
End Plate	EPCP3L2.5	30	EPCP3L2.5	30	EPCP3L2.5	30	EPCP3L2.5	30
DIN Rail	2511120	20	2511120	20	2511120	20	2511120	20
	CA701-15/S	20	CA701-15/S	20	CA701-15/S	20	CA701-15/S	20
End Stop	CA202 / CA103	50	CA202 / CA103	50	CA202 / CA103	50	CA202 / CA103	50
Marking Tag	MT2G	1 Pk. (100 tags)	MT2G	1 Pk. (100 tags)	MT2G	1 Pk. (100 tags)	MT2G	1 Pk. (100 tags)

 CP4LG2.5

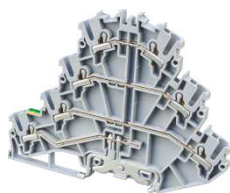

4 Level Terminal Block
Bottom Ground

Dimensions & Weight

Width / Length	5 mm / 118.6 mm
Height w DIN Rail	35 x 7.5 mm
	35 x 15 mm
Weight per piece	26.5 g

Technical Data/Ratings

Approvals		
Wire Size (solid / stranded)	22-12 AWG	0.34-2.5 mm ²
Voltage Rating	300 V	500V
Current Rating	20 A (Top 3 Levels)	24 A (Top 3 Levels)
Insulation Material	Polyamide 66	

Installation Instructions

Wire Stripping Length	10 mm
Screwdriver	SCM0.4/2.5 (0.4 x 2.5 mm blade)

Terminal Blocks	Cat. No.	Std. Pk.
Ground/ Earth Yellow / Green 	CP4LG2.5	30

Jumpers	Cat. No.	Imax	Std. Pk.
Shorting Link/	2 pole	CA801/A2	24A 100
Jumpers	3 pole	CA801/A3	24A 100
	4 pole	CA801/A4	24A 100
	10 pole	CA801/A10	24A 10

Accessories	Cat. No.	Std. Pk.
End Plate	EPCP4LG2.5	30
DIN Rail	2511120	20
	CA701-15/S	20
End Stop	CA202 / CA103	50
Marking Tag	MT2G	1 Pk. (100 tags)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[EPCP3L2.5](#) [EPCP4LG2.5](#)