 

 
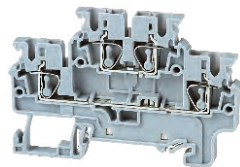


CXDL2.5





Double Level Terminal with 2 feed through circuits. Jumpers and Marking at both levels.

CXDL2.5(I.S)

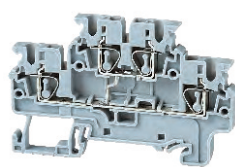



Internally shorted Double Level Terminal for distribution applications.

 CXDLG2.5

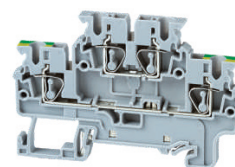

Double Level Terminal with grounding circuit on the lower level and standard feed through at the top level.

 CXDLG2.5(I.S)

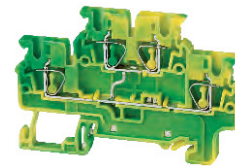

Double Level Ground Terminal Block internally shorted with 4 grounding connections.

Dimensions

Width	5 mm	5 mm	5 mm	5 mm
Length	71 mm	71 mm	71 mm	71 mm
Height w DIN Rail	35 x 7.5 mm 35 x 15 mm	49.5 mm 57 mm	49.5 mm 57 mm	49.5 mm 57 mm

Technical Data/Ratings

Approvals				
Wire Size (solid stranded)	24-12 AWG 0.2-2.5 mm ²	24-12 AWG 0.2-2.5 mm ²	24-12 AWG 0.2-2.5 mm ²	24-12 AWG 0.2-2.5 mm ²
Voltage Rating	600 V 1000 V	600 V 1000 V	600 V 1000 V	600 V 1000 V
Current Rating	20 A 24 A	20 A 24 A	20 A 24 A	20 A 24 A
Insulation Material	Polyamide 66	Polyamide 66	Polyamide 66	Polyamide 66

Installation Instructions

Wire Stripping Length	10 mm	10 mm	10 mm	10 mm
Screwdriver	0.5x3 mm	0.5x3 mm	0.5x3 mm	0.5x3 mm

Terminal Blocks

	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Grey (standard)	CXDL2.5	50	CXDL2.5(I.S)	50	CXDLG2.5	50	CXDLG2.5(I.S)	50
Red R	CXDL2.5/R	50	CXDL2.5(I.S)/R	50			Yellow / Green	
Blue BU	CXDL2.5/BU	50	CXDL2.5(I.S)/BU	50				
Black BL	CXDL2.5/BL	50	CXDL2.5(I.S)/BL	50				
Orange O	CXDL2.5/O	50	CXDL2.5(I.S)/O	50				
Green G	CXDL2.5/G	50	CXDL2.5(I.S)/G	50				
Yellow Y	CXDL2.5/Y	50	CXDL2.5(I.S)/Y	50				
White W	CXDL2.5/W	50	CXDL2.5(I.S)/W	50				

Accessories

	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
End Plate	EPCXDL2.5	50	EPCXDL2.5	50	EPCXDL2.5	50	EPCXDL2.5	50
Partition Plate	—	—	—	—	—	—	—	—
DIN Rail	2511120 CA701-15/S	20 20	2511120 CA701-15/S	20 20	2511120 CA701-15/S	20 20	2511120 CA701-15/S	20 20
End Stop	CA702 CA802 CA103	50 50 50	CA702 CA802 CA103	50 50 50	CA702 CA802 CA103	50 50 50	CA702 CA802 CA103	50 50 50
Shorting Link/ Jumpers	2 pole JX2.5/2 3 pole JX2.5/3 4 pole JX2.5/4 10 pole JX2.5/10	100 50 50 10	JX2.5/2 JX2.5/3 JX2.5/4 JX2.5/10	100 50 50 10	JX2.5/2 JX2.5/3 JX2.5/4 JX2.5/10	100 50 50 10	JX2.5/2 JX2.5/3 JX2.5/4 JX2.5/10	100 50 50 10
Warning Label	WLX2.5	100	WLX2.5	100	WLX2.5	100	WLX2.5	100
Test Plug	TX2.5	50	TX2.5	50	TX2.5	50	TX2.5	50
Marking Tag	MT5	100	MT5	100	MT5	100	MT5	100

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Altech:

[CXDL2.5](#) [CXDL2.5/R](#) [CXDL2.5\(I.S\)/G](#) [CXDL2.5/W](#) [CXDL2.5\(I.S\)/R](#) [CXDL2.5/O](#) [CXDL2.5/BU](#) [CXDL2.5\(E\)D2](#)
[CXDL2.5/BL](#) [CXDL2.5\(E\)DD1](#) [CXDL2.5\(I.S\)/BU](#) [CXDLG2.5](#) [CXDL2.5\(I.S\)/BL](#) [CXDL2.5\(E\)LD1/6-60V](#)
[CXDL2.5\(I.S\)/W](#) [CXDLG2.5\(I.S\)](#) [CXDL2.5\(I.S\)](#) [CXDL2.5\(E\)D1](#) [CXDL2.5/Y](#) [CXDL2.5\(I.S\)/O](#) [CXDL2.5/G](#)
[CXDL2.5\(I.S\)/Y](#) [CXDL2.5\(E\)DD4](#)