

Standard Features

- **Protection Level:** IP54* / IP65**
- **Technical:** Knockout Sidewalls
Tinted Transparent Door
Multiple Enclosure Combination Option
- **Enclosure Material:** Polystyrene
- **Door Material:** Polycarbonate
- **Gasket Material:** Polyurethane
- **Temperature Range:** -40°C to 70°C (-40°F to 158°F)
- **Color:** Light Gray
- **Included Accessories:** 35mm DIN Rail, 3 Pole Ground/Neutral Terminal Strip
2 ea. 9mm (0.35 in.) Filler Strips
3 ea. Pg16 Entry Spouts
Label Strip
- **Accessories:** See section below



* With Supplied Entry Spouts
**As Equipped or With Optional IP65 Cable Glands


EK

Ordering Information	Cat. No.	Type	Length	Dimensions mm (in) Width	Height	Std. Pk.
Enclosure	542-402	EK002	130 mm (5.12 in)	94 mm (3.70 in)	80 mm (3.15 in)	1

Accessories

Ordering Information	Cat. No.	Type	Std. Pk.
Key Lock	548-102	KL	1
Terminal	X-573	PE/N Terminal - 3 pole	1

Please refer to pages 106-113 for additional accessories and detailed information.

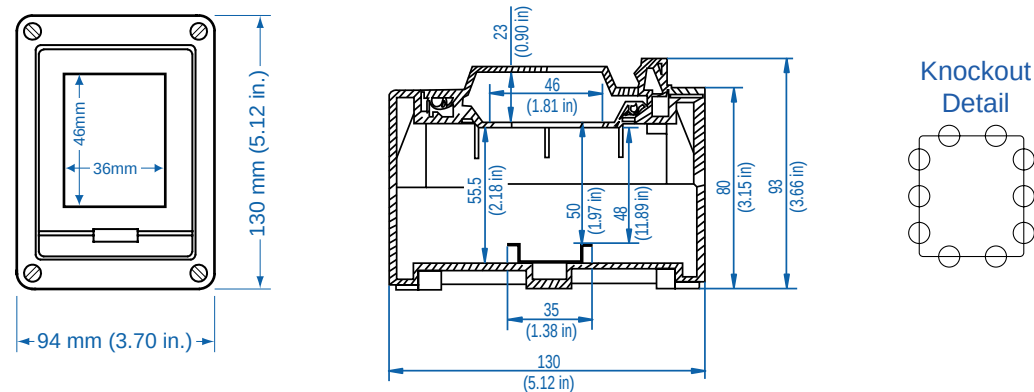

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[542-402](#)