

Standard Features

- **Protection Level:** IP65 - Nema Type 4x
- **Technical:** Fits 12 Circuit Breaker Poles  
Smooth Sidewalls  
Tinted Transparent Door
- **Enclosure Material:** Polycarbonate
- **Door Material:** Polycarbonate
- **Gasket Material:** Polyurethane
- **Material**
- **Temperature Range:** -40°C to 120°C (-40°F to 248°F)
- **Color:** Light Gray
- **Included Accessories:** 35mm DIN Rail  
Label Strip
- **Accessories:** See section below




EK

| Ordering Information | Cat. No. | Type  | Length           | Dimensions mm (in) |  | Height           | Std. Pk. |
|----------------------|----------|-------|------------------|--------------------|--|------------------|----------|
|                      |          |       |                  | Width              |  |                  |          |
| Enclosure            | 542-512  | EK012 | 180 mm (7.09 in) | 254 mm (10.00 in)  |  | 110 mm (4.33 in) | 1        |

Accessories

| Ordering Information | Cat. No. | Type                                                     | Std. Pk. |
|----------------------|----------|----------------------------------------------------------|----------|
| Terminal             | 790-211  | PE/N Terminal - 2x12 pole (2x16 / 10x6 mm <sup>2</sup> ) | 1        |
| Filler Strip         | 799-012  | 108 mm piece (6 divisions)                               | 1        |

Please refer to pages 149-152 for additional accessories and detailed information.

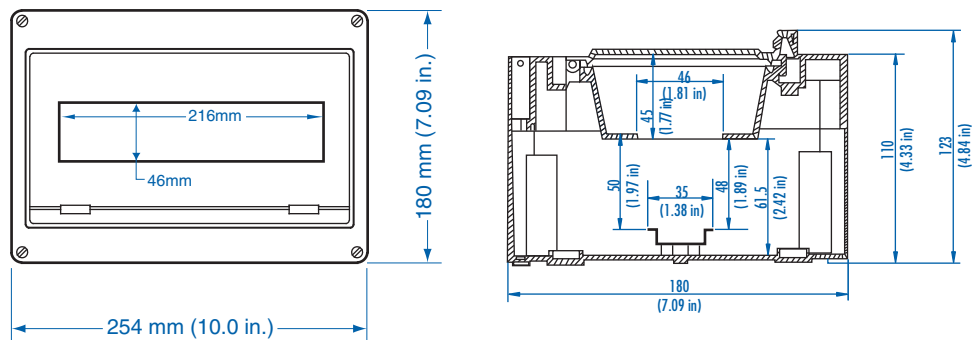

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[542-412](#) [542-512](#)