

# Interface Modules

## Diode modules & component carriers




### INTERFACES

#### BSM Component Carrier 35 or 32 mm DIN Rail Mount with solder posts

##### Technical Information

Current .....6 A (12 A Bus)  
Terminal.....15 A  
Voltage .....250V AC  
Wire Range .....0.5-4 mm<sup>2</sup> / 22-14 AWG  
Torque .....0.5-4 Nm / 4 lbs-in.  
Stripping Length ...8 mm


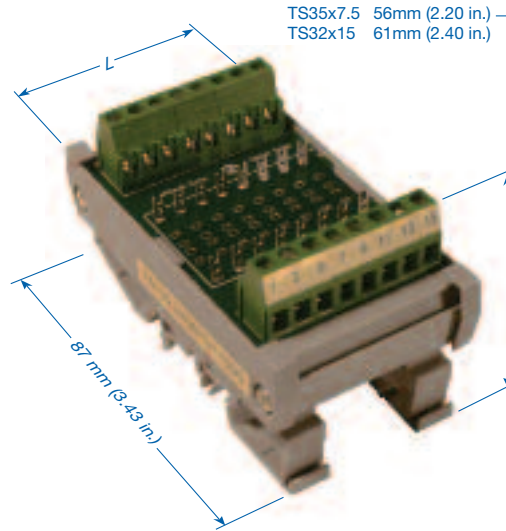


#### SCREW CLAMP

| Part Number | Type    | No. of Poles | Module Length (L) in mm(in.) | Std. Pk. |
|-------------|---------|--------------|------------------------------|----------|
| 5700.2      | BSM8-S  | 16           | 47 (1.85)                    | 1        |
| 5701.2      | BSM12-S | 24           | 69 (2.72)                    | 1        |

#### SPRING CLAMP

| Part Number | Type    | No. of Poles | Module Length (L) in mm(in.) | Std. Pk. |
|-------------|---------|--------------|------------------------------|----------|
| 5700.2/S    | BSM8-S  | 16           | 47 (1.85)                    | 1        |
| 5701.2/S    | BSM12-S | 24           | 69 (2.72)                    | 1        |

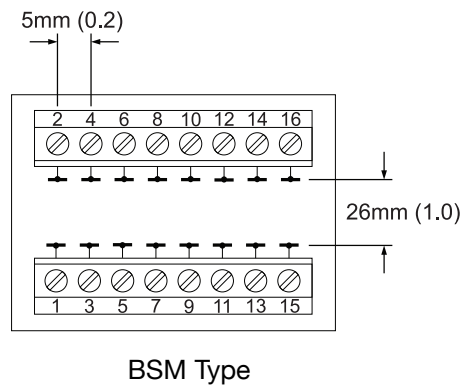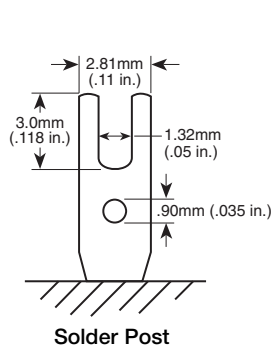

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[5701.2](#) [5700.2](#) [5701.2/S](#)