

Interface Modules

Diode modules & component carriers

INTERFACES


Dip Socket Carrier - 3 Amp 35 or 32mm DIN Rail Mount

Typical Applications:

14 Pin
Magnecraft® Classes 107, 171, 172;
S-D® Series MRR-D; Hamlin® 700;
Dale® TDP14 Resistors; etc.

16 Pin
Most P&B® including T85 Hi Sens and
I/O Modules IA, OA, OD16;
Midtex® 190 Power;
Augat® Alcoswitch® GD, AD Series, etc.

20 Pin
C&K® BD series switches;
Grayhill® 79 coded switches;
AMP® 7600 shunts; etc.

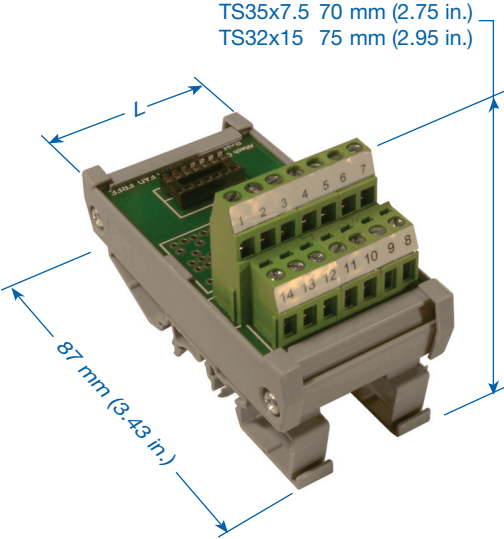

Technical Information

Current3 A^a
Voltage250V AC
Wire Range0.5-4 mm² / 22-12 AWG
Torque0.5-4 Nm / 4 lbs-in.
Stripping Length ...8 mm


SCREW CLAMP

Part Number	Type	No. of Poles	Module Length (L) in mm(in.)	Std. Pk.
8937.2	DIPC14	14	45 (1.77)	1
8938.2	DIPC16	16	68 (2.68)	1
8939.2	DIPC20	20	68 (2.68)	1

SPRING CLAMP

Part Number	Type	No. of Poles	Module Length (L) in mm(in.)	Std. Pk.
8937.2/S	DIPC14	14	45 (1.77)	1
8938.2/S	DIPC16	16	56 (2.20)	1
8939.2/S	DIPC20	20	56 (2.20)	1

PTH holes for convenient
component insertion and
easy soldering.

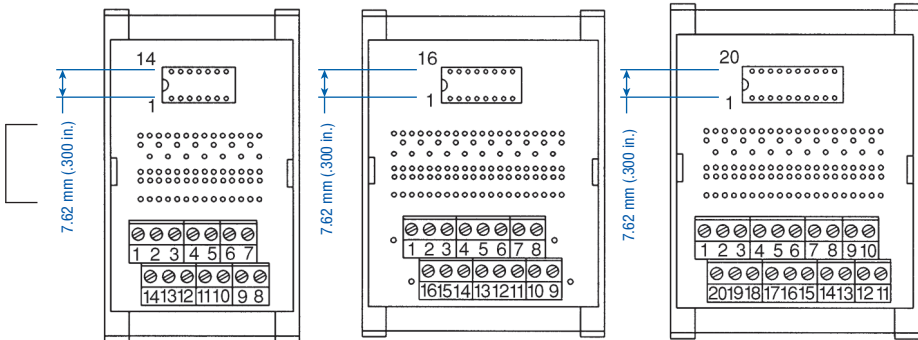

^a Current Ratings
Printed Circuit Traces: 3.5A
Terminal Blocks: 15A
Dip Socket: 3A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[8937.2](#) [8939.2](#) [8938.2](#)