



## Coded switches



<b>3 m PVC cable</b>					
Designation			MAK-4236-3		
<b>Part number</b>			<b>649.0642.301</b>		
Delivery: ex-stock/bult to order			●/—		
<b>6 m PVC cable</b>					
Designation			MAK-4236-6		
<b>Part number</b>			<b>649.0642.302</b>		
Delivery: ex-stock/bult to order			●/—		
<b>9 m PVC cable</b>					
Designation			MAK-4236-9		
<b>Part number</b>			<b>649.0642.303</b>		
Delivery: ex-stock/bult to order			●/—		
<b>Plug RD 6.5 mm/4 poles</b>					
Designation			MAK-4236-STK		
<b>Part number</b>			<b>649.0642.305</b>		
Delivery: ex-stock/bult to order			●/—		
<b>Switching capacity</b>					
Operating voltage		max.	DC 30 V		DC 30 V
Switching capacity		max.	250 mW		250 mW
<b>Ambient conditions</b>					
Temperatur range		min./max.	−5 °C/+70 °C		−5 °C/+70 °C
			+23 °F/+158 °C		+23 °F/+158 °C
Protection class (according to IEC 529, EN 60529)			IP 67		IP 67
Housing material			PA 6.6		PA 6.6
<b>Sensing distance</b>		S on min.	5 mm		3 mm
		S off max.	14 mm		14 mm
<b>Operating magnet</b>					
Designation			TK-42-CD		TK-42-CD-SN8
<b>Part number</b>			<b>640.2042.301</b>		<b>640.2042.306</b>
To be used MÜZ					
see page			256–257		256–257

All dimensions in mm

Other versions available on request.  
SW: wrench size

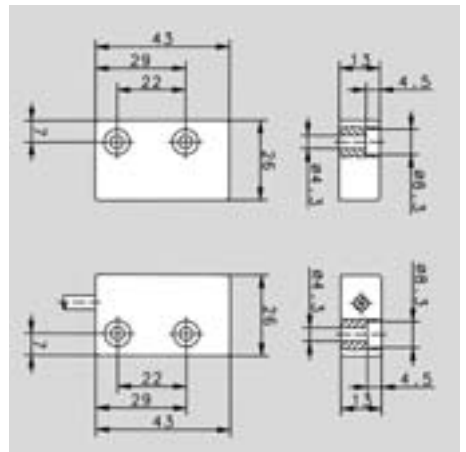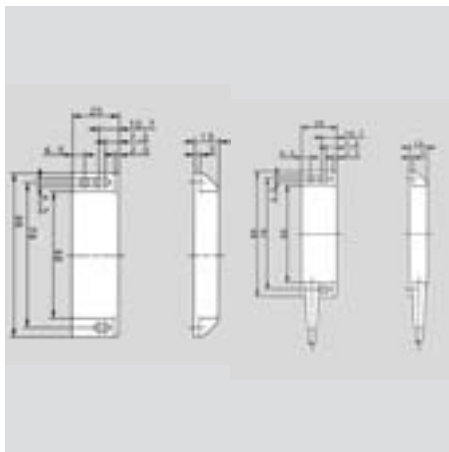

Coded switches



3 m PVC cable		
Designation		
Part number		
Delivery: ex-stock/bult to order		
6 m PVC cable		
Designation		
Part number		
Delivery: ex-stock/bult to order		
9 m PVC cable		
Designation		
Part number		
Delivery: ex-stock/bult to order		
Plug M 12/4 poles		
Designation		
Part number		
Delivery: ex-stock/bult to order		
Switching capacity		
Operating voltage	max.	DC 30 V
Switching capacity	max.	250 mW

Ambient conditions		
Temperatur range	min./max.	-5 °C/+70 °C
Protection class (according to IEC 529, EN 60529)		
Housing material		
Sensing distance		
S on	min.	3 mm
S off	max.	10 mm

Operating magnet		
Designation		
Part number		

To be used MÜZ		
see page		

All dimensions in mm


Other versions available on request.

MAK-5336-3		
649.0653.310		
●/-		
MAK-5336-6		
649.0653.311		
●/-		
MAK-5336-9		
649.0653.312		
●/-		
MAK-5336-STK		
649.0653.313		
●/-		

-5 °C/+70 °C		
+23 °F/+158 °C		
IP 67		
PA 6.6		
3 mm		
10 mm		

TK-43-CD		
640.2043.023		

256-257		
---------	--	--

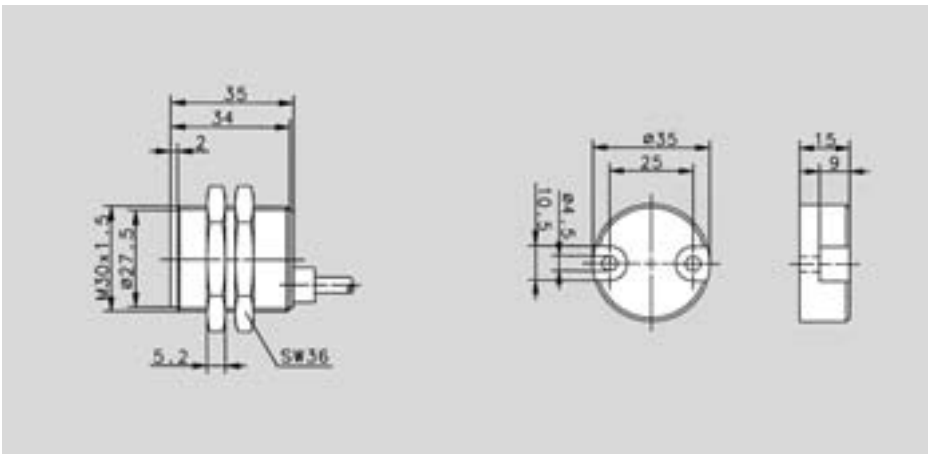

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Altech:

[630.3263.016](#) [630.2357.061](#) [640.2042.061](#) [630.1268.028](#) [630.2142.076](#) [630.5121.064](#) [640.8043.065](#)  
[640.2052.066](#) [640.2052.307](#) [630.1167.054](#) [640.2100.014](#) [630.3111.001](#) [630.1368.033](#) [630.1106.065](#) [640.2043.064](#)  
[630.2145.077](#) [630.1162.059](#) [640.4167.017](#) [630.2121.070](#) [630.2100.053](#) [640.2042.306](#) [630.3131.073](#)  
[630.1262.039](#) [640.8043.070](#) [640.2042.053](#) [640.2169.038](#) [630.2144.071](#)