


Cable Clamps. Eye-bolts & Hardware

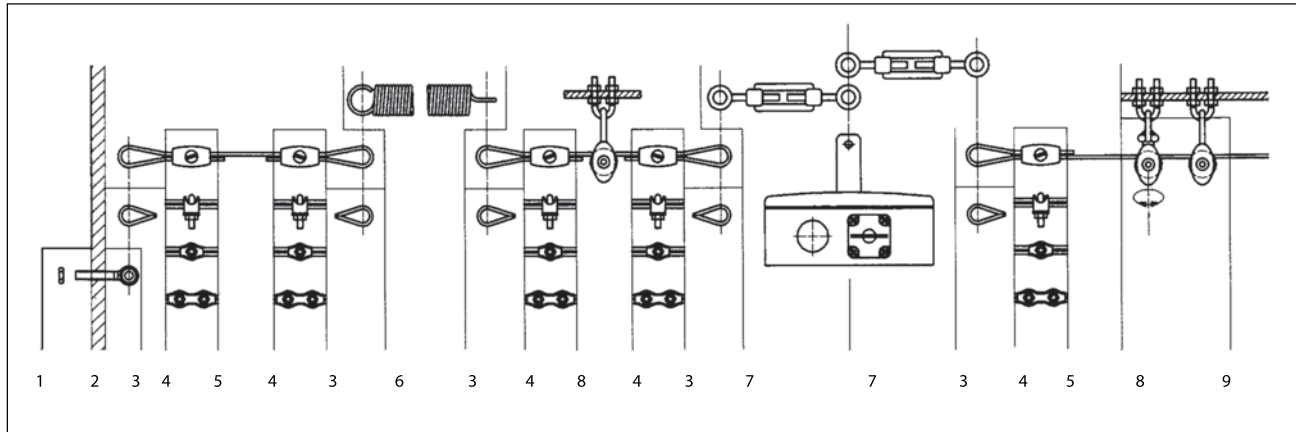

1 Nut



Size	Strength class	Art. No.
M 6 DIN 439T2	A2-70	260.0439.090
M 8 DIN 439T2	04	260.0439.187
M 10 DIN 934	8	260.0934.092

Coating: Thick-layer passivated (M 8/M 10), Ros-compliant

2 Eye bolt



Size	Strength class	Art. No.
M 10 x 50	4.6	260.0444.076
M 6 x 50	4.6	260.0444.185
M 8 x 50	4.6	260.0444.186

Coating: Thick-layer passivated, RoHs-compliant

3 Cable eye stiffener

 


Size	Art. No.
D 2.5 to DIN 65457	269.6899.013
D 3 to DIN 65457	269.6899.014
D 4 to DIN 65457	269.6899.015
D 5 to DIN 6899B	269.6899.001

Material: Steel strip

Coating: Blue passivated, RoHs-compliant

4 Cable grip

 


Size	Art. No.
D5	269.0741.002

Material: GTW/steel

Coating: Yellow chromed, RoHs-compliant

4 Cable grip, oval

 


Size	LG	BR	H1	H2	Art. No.
2	28 mm	15 mm	11 mm	13 mm	269.0000.004
3	28 mm	15 mm	12 mm	13 mm	269.0000.005
4	34 mm	20 mm	14 mm	18 mm	269.0000.006

Material: Refined zinc cast alloy

Coating: Blue passivated, RoHs-compliant

4 Cable grip, simplex



Size	LG	BR	H1	H2	Art. No.
2	15 mm	12 mm	5 mm	11 mm	269.0000.007
3	17 mm	14 mm	6 mm	14 mm	269.0000.008
4	20 mm	17 mm	7 mm	16 mm	269.0000.009

Material: Steel strip

Coating: Blue passivated, RoHs-compliant

Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[260.0934.092](#) [260.0444.186](#) [260.0439.187](#) [260.0439.090](#) [260.0444.076](#) [260.0444.185](#) [269.0741.002](#)
[269.6899.013](#) [269.0000.007](#) [269.6899.014](#) [269.0000.005](#) [269.0000.008](#) [269.0000.009](#) [269.6899.015](#) [269.6899.001](#)
[269.0000.006](#) [269.0000.004](#)