



IF Series

IW

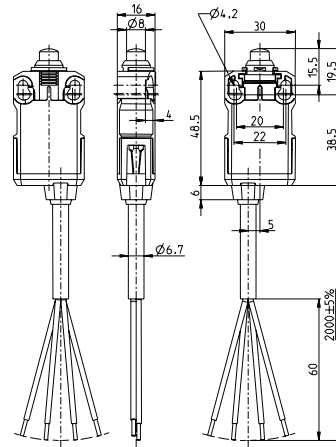

RIW

 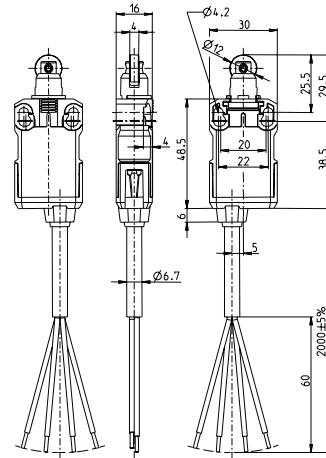


Switching Operation

1 NC / 1 NO Contacts


Slow Action

608.9102.001
IF-U1Z IW




Snap Action

 608.9152.006
IF-SU1Z IW




Slow Action

 608.9117.002
IF-U1Z RIW




Snap Action

 608.9167.007
IF-SU1Z RIW



2 NC Contacts

 
608.9802.011
IF-A2Z IW



-

-

 608.9817.012
IF-A2Z RIW



-

-

2 NO Contacts

-

-

-

-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	10A	10A
B10d	6 Million	6 Million
Mechanical Service Life	3 x 10 ⁶	3 x 10 ⁶
Switching Frequency	≤ 30/min	≤ 30/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP67	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC	240VAC

Approvals



Special features / variants

Slow Action

240V	240V
10A	10A
6 Million	6 Million
3 x 10 ⁶	3 x 10 ⁶
≤ 30/min	≤ 300/min
-30 °C to +80 °C	-30 °C to +80 °C
IP67	IP67
AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
240VAC	240VAC

Snap Action



Special features / variants

- Actuator can be turned in steps of 90°

Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[608.9817.012](#) [608.9802.011](#)