



IF Series

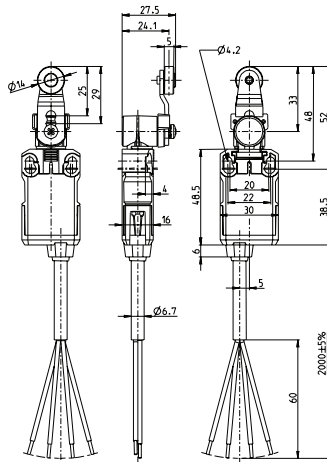

AH



IWF

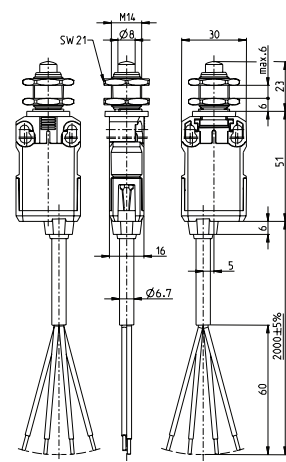


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.9135.003
IF-U1Z AH




Snap Action

 608.9185.008
IF-SU1Z AH




Slow Action

 608.9102.004
IF-U1Z IWF




Snap Action

 608.9152.009
IF-SU1Z IWF




2 NC Contacts

 
608.9835.013
IF-A2Z AH



 
608.9885.041
IF-SA2Z AH



 608.9802.014
IF-A2Z IWF



 608.9852.043
IF-SA2Z IWF



2 NO Contacts

-

-

-

-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	10A	10A
B10d	6 Million	6 Million
Mechanical Service Life	3 x 10 ⁶	3 x 10 ⁶
Switching Frequency	≤ 30/min	≤ 30/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP67	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC	240VAC

Approvals



Special features/variants

- Actuator can be turned in steps of 90°

Slow Action

240V	240V
10A	10A
6 Million	6 Million
3 x 10 ⁶	3 x 10 ⁶
≤ 30/min	≤ 30/min
-30 °C to +80 °C	-30 °C to +80 °C
IP67	IP67
AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
240VAC	240VAC



Special features/variants

- Front mounting

Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[608.9802.014](#) [608.9885.041](#) [608.9852.043](#) [608.9835.013](#) [608.9135.003](#)