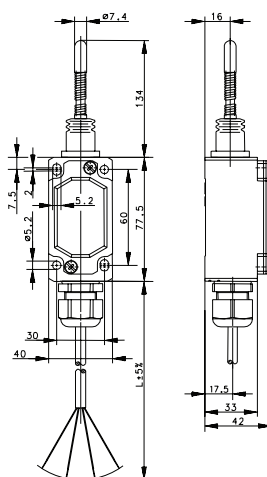
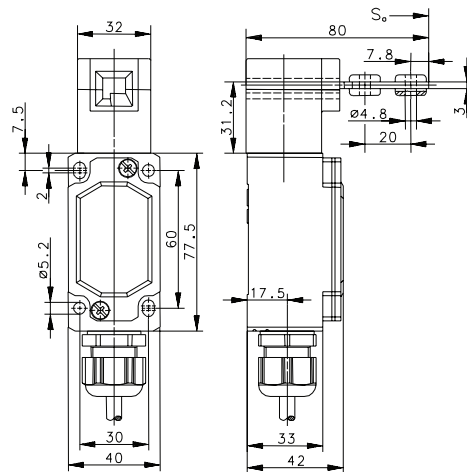


 
ENM2 Series Limit Switches and Keyed Safety Switches

ENM2 FF

ENM2 VTW

6.5' (2 meter) connection cable
609.7190.097
 ENM2-SU1 EX FF -2M-

16.4' (5 meter) connection cable
609.7190.099
 ENM2-SU1 EX FF -5M-

619.7100.010
 ENM2-SU1Z EX VTW -5M-

29.5' (9 meter) connection cable
609.7190.100
 ENM2-SU1 EX FF -9M-

EX Certification


Technical Information

Maximum Switching Voltage	230V	230V
Maximum Switching Amperage	5A	5A
B10d	4 Million	4 Million
Mechanical Service Life	2 x 10 ⁶	2 x 10 ⁶
Switching Frequency	≤ 50/min	≤ 50/min
Operating Temperature	-20 °C to +65 °C	-20 °C to +65 °C
Protection Rating	IP66 / IP67	IP66 / IP67
Utilization Category	AC 15, 240 V / 3 A; DC 13, 250 V / 0.27 A	AC 15, 240 V / 3 A; DC 13, 250 V / 0.27 A
Rate Insulation Voltage	250VAC	250VAC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[609.7190.097](#) [609.7190.099](#) [609.7190.100](#) [619.7100.010](#)