



GC Series Limit Switches

GC IW

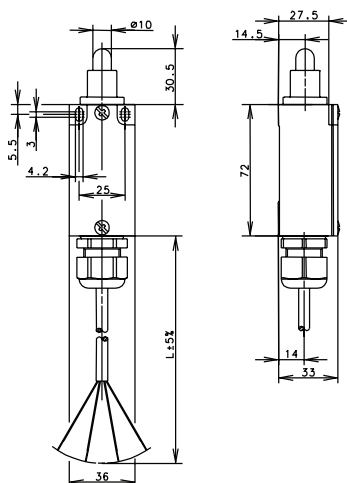


6.5' (2 meter) connection cable

 609.2152.002
GC-SU1Z EX IW -2M-




GC HW

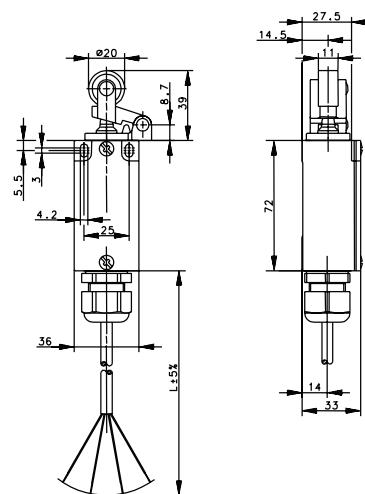

-

16.4' (5 meter) connection cable

 609.2152.004
GC-SU1Z EX IW -5M-




609.2171.024
GC-SU1Z EX HW -5M-




29.5' (9 meter) connection cable

 609.2152.005
GC-SU1Z EX IW -9M-



 609.2171.025
GC-SU1Z EX HW -9M-



EX Certification

Ex II 2 G EEx d IIC T6

Ex II 2 G EEx d IIC T6

Technical Information

Maximum Switching Voltage
Maximum Switching Amperage
B10d
Mechanical Service Life
Switching Frequency
Operating Temperature
Protection Rating
Utilization Category
Rate Insulation Voltage

230V
5A
4 Million
2 x 10⁶
≤ 50/min
-20 °C to +65 °C
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC

230V
5A
4 Million
2 x 10⁶
≤ 50/min
-20 °C to +65 °C
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[609.2152.005](#) [609.2171.025](#) [609.2171.024](#) [609.2152.002](#) [609.2152.004](#)