



IF Series



RIWF

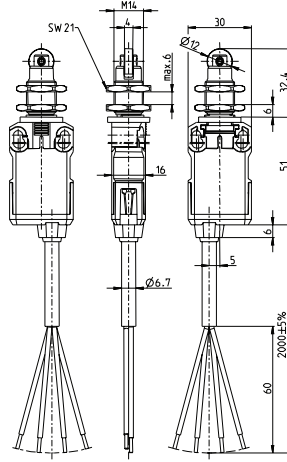

IW AMP4

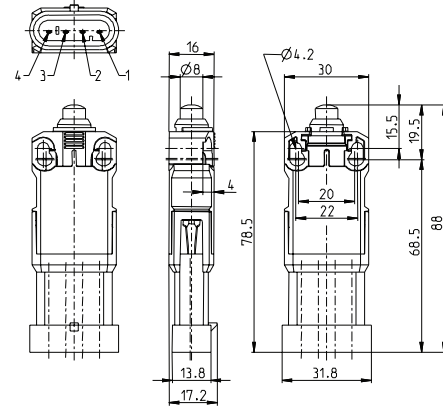


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.9117.005
IF-U1Z RIWF




Snap Action

 608.9167.010
IF-SU1Z RIWF




Slow Action

 608.9102.016
IF-U1Z IW AMP4




Snap Action

 608.9152.021
IF-SU1Z IW AMP4



2 NC Contacts

 
608.9817.015
IF-A2Z RIWF



-

-

 608.9802.026
IF-A2Z IW AMP4



-

-

2 NO Contacts

-

-

-

-

-

-

-

-

1 NC / 1NO Contacts Overlapping

-

-

-

-

-

-

-

-

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	10A	10A
B10d	6 Million	6 Million
Mechanical Service Life	3 x 10 ⁶	3 x 10 ⁶
Switching Frequency	≤ 30/min	≤ 30/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP67	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC	240VAC

Approvals



Special features/variants

- Front mounting
- Actuator can be turned in steps of 90°

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	10A	10A
B10d	6 Million	6 Million
Mechanical Service Life	3 x 10 ⁶	3 x 10 ⁶
Switching Frequency	≤ 30/min	≤ 30/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP67	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC	240VAC



Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[608.9802.026](#) [608.9817.015](#) [608.9102.016](#) [608.9152.021](#)