


SN2 Series Limit Switch and Double Sided Cable Pull Switch

SN2 Limit Switch without Cable


Series SI2 Double Sided Rope Pull

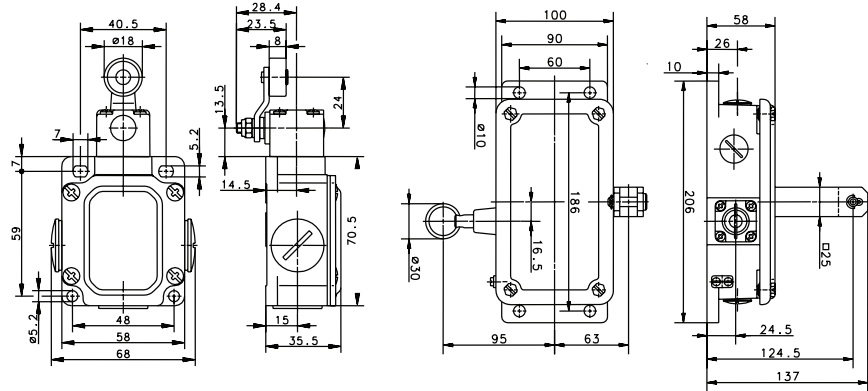

1 NC / 1 NO contact

619.3285.001
 SN2-SU1Z AH EXD 180 Gr.

-
-

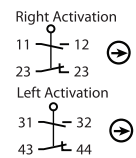609.1288.024
 SI2-U2Z AK EXD


2 NC / 2 NO contacts

-
-

-
-

EX Certification

Ex II 2 D IP65 T 85 °C

Ex II 3 D Ex tD A22 IP65 T 80°C

Technical Information

Maximum Switching Voltage

240V

240V

Maximum Switching Amperage

10A

10A

B10d

20 Million

4 Million

Mechanical Service Life

10 x 10⁶

2 x 10⁶

Switching Frequency

≤ 60/min

≤ 10/min

Operating Temperature

-20 °C to +80 °C

-20 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category

AC 15, 240 V / 3 A;
 DC 13, 250 V / 0.27 A

AC 15, 240 V / 3 A;
 DC 13, 250 V / 0.27 A

Rate Insulation Voltage

400VAC

400VAC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[609.1288.024](#) [619.3285.001](#)