



IF Series

RIW AMP4

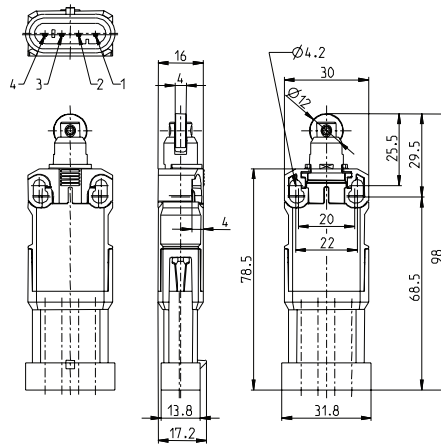

IWF AMP4

 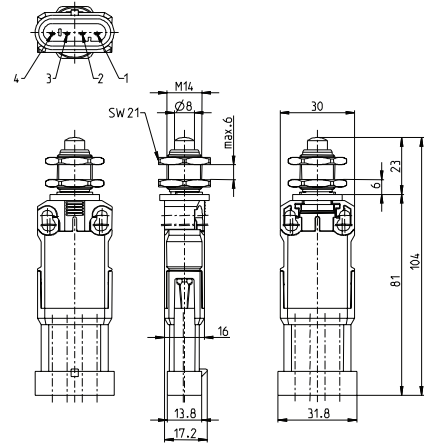


Switching Operation

1 NC / 1 NO Contacts


Slow Action

608.9117.017
IF-U1Z RIW AMP4




Snap Action

 608.9167.022
IF-SU1Z RIW AMP4




Slow Action

 608.9102.019
IF-U1Z IWF AMP4




Snap Action

 608.9152.024
IF-SU1Z IWF AMP4



2 NC Contacts

 
608.9817.027
IF-A2Z RIW AMP4



-

-

 608.9802.029
IF-A2Z IWF AMP4



-

-

2 NO Contacts

-

-

-

-

-

-

-

-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

-

-

-

-

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage	240V
Maximum Switching Amperage	10A
B10d	6 Million
Mechanical Service Life	3 x 10 ⁶
Switching Frequency	≤ 30/min
Operating Temperature	-30 °C to +80 °C
Protection Rating	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC

Approvals



Special features/variants

- Actuator can be turned in steps of 90°

Slow Action

Snap Action

240V	240V
10A	10A
6 Million	6 Million
3 x 10 ⁶	3 x 10 ⁶
≤ 30/min	≤ 30/min
-30 °C to +80 °C	-30 °C to +80 °C
IP67	IP67
AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
240VAC	240VAC



Special features/variants

- Front mounting
- With roller over switch

Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[608.9102.019](#) [608.9167.022](#) [608.9152.024](#) [608.9817.027](#) [608.9802.029](#) [608.9117.017](#)