



Bi2 Series



HW RO13.5

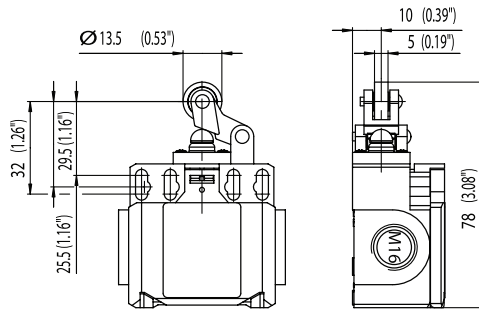

FF

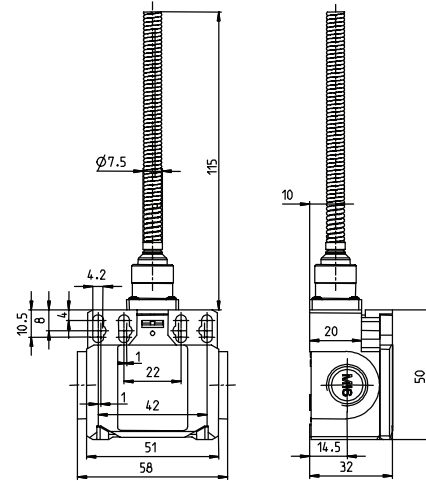

Switching Operation

 
1 NC / 1 NO Contacts

Slow Action

-


Snap Action

608.5171.109
BI2-SU1Z HW RO13.5




Slow Action

 618.5140.104
BI2-U1 FF



Snap Action

 608.5190.114
BI2-SU1 FF



2 NC Contacts

-

-

-

-

2 NO Contacts

-

-

-

-

**1 NC / 1 NO Contacts
Overlapping**

-

-

-

-

Replacement actuator:

391.1890.681

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals



Special features/variants (on request)

- Available with different spring lengths
- Spring rod
- Various spring versions

Drawing dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[608.5171.109](#) [608.5190.114](#) [618.5140.104](#)