
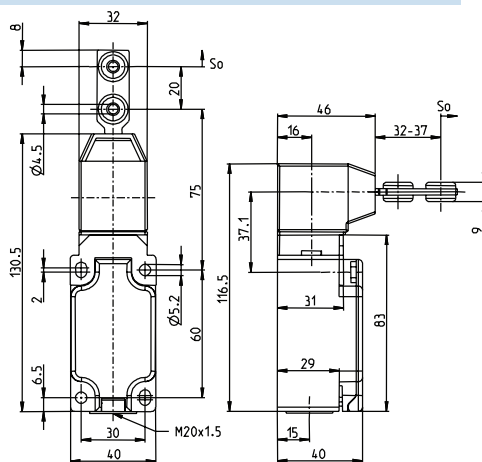



ENK

A1 ACTUATOR KEY
391.1702.228

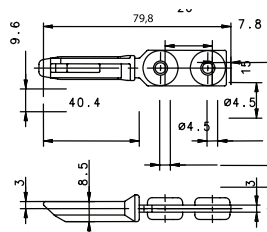


15.7" Minimum Bend Radius

A2 ACTUATOR KEY
391.1702.229

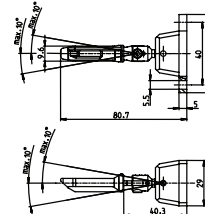


5.9" Minimum Bend Radius

A3 ACTUATOR KEY
391.1702.230

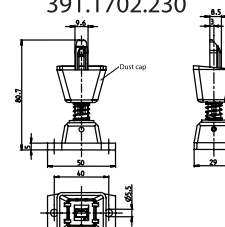

15.7" Minimum Bend Radius

A4 ACTUATOR KEY
391.1702.231

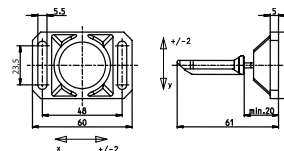

13.8" Minimum Bend Radius

Technical Information

Maximum Switching Voltage	240V		
Max. Switching Amps (up to)*	10A		
B10d (up to)*	20 Million		
Mechanical Service Life (up to)*	10 x 10 ⁶		
Switching Frequency	≤ 30/min		
Operating Temperature	-30 °C to +80 °C		
Protection Rating	IP65		
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A		
Rate Insulation Voltage	250VAC		

Approvals

* Depending on switching system - see technical information for details



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[601.6669.133](#) [601.6669.154](#) [601.6619.132](#)