 



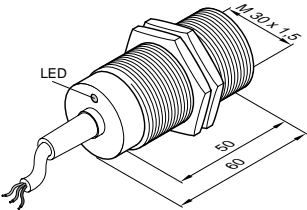
**AC - 2 WIRE - EXTENDED
VOLTAGE RANGE – Brass, Nickel
Plated (BN), and TROGAMID T
Cylindrical, Threaded,
20-250V AC, 500 mA,
1 LED for Output Energized**

- **Higher Current Rating**
- **Wider Voltage Range**
- **Carries C€ mark**
- IEC (529) IP67 (NEMA 1, 3, 4, 6, 12, 13) Protection
- Temperature Range: -25 to 70°C (-13 to 158°F)


M30 Flush Mount			
Sensing Distance		10mm (0.39 in.)	
Cable or Connector Style Cat. No.	Cable	Cable	68
Normally Open 	9916-2600	9916-2900	9916-2668
Normally Closed 	9916-2100	9916-2400	9916-2168
Voltage Range	20V-250V	20V - 250V	20V - 250V
Operating Frequency	50/60Hz	50/60Hz	50/60Hz
Supply Current	2 mA	2 mA	2 mA
Max. Load Current	500 mA	500 mA	500 mA
Voltage Drop Across Sensor	≤5V	≤5V	≤5V
Max. Leakage Current	≤2mA	≤2mA	≤2mA
Short Term Current (20 ms, 1Hz)	8A	8A	8A
Switching Frequency	15Hz	15Hz	15Hz
Hysteresis	≤15%	≤15%	≤15%
Temperature Drift	≤10%	≤10%	≤10%
Repeatability	1mm (.039 in.)	1mm (.039 in.)	1mm (.039 in.)
Front Cap Material	PBTP	PBTP	PBTP
Housing Material	Nickel Plated Brass	Trogamid T	Nickel Plated Brass

Nickel Plated Brass Housings


Fixed Cable
PVC 2m (6ft. 6in.). For 5m (16 ft. 5 in.) cable length, change the last two digits of the part number to 02. For other cable lengths and/or PUR cable, please consult Altech. Supplied with non-metallic locknuts for Trogamid T housings and Brass, Nickel Plated (BN) locknuts for Nickel Plated Brass housings.



Trogamid T Housings

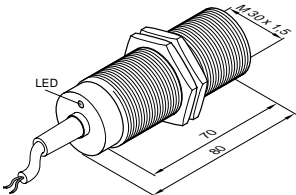

68 Style Connectors
3-pin, Micro style, 12mm (.47 in.) supplied with Brass, Nickel Plated (BN) locknuts.

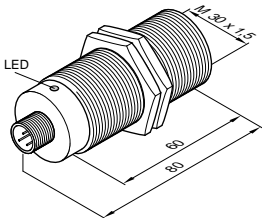

Metric/in. Conversion Table




1.5 mm = .06 in.	50.0 mm = 1.96 in.
12.0 mm = .47 in.	58.0 mm = 2.28 in.
30.0 mm = 1.18 in.	60.0 mm = 2.36 in.
38.0 mm = 1.50 in.	80.0 mm = 3.15 in.
48.0 mm = 1.89 in.	

This table converts millimeters to inches in reference to the illustrations included on these pages.

M30 Non-Flush Mount 15mm (0.59 in.)

Cable	Cable	68
9916-2700	9916-3000	9916-2768
9916-2300	9916-2500	9916-2368
20V - 250V	20V - 250V	20V - 250V
50/60Hz	50/60Hz	50/60Hz
2 mA	2 mA	2 mA
500 mA	500 mA	500 mA
≤5V	≤5V	≤5V
≤2mA	≤2mA	≤2mA
8A	8A	8A
15Hz	15Hz	15Hz
≤15%	≤15%	≤15%
≤10%	≤10%	≤10%
1.5mm (.059 in.)	1.5mm (.059 in.)	1.5mm (.059 in.)
PBTB	PBTB	PBTB
Nickel Plated Brass	Trogamid T	Nickel Plated Brass

Note: Sensor dimensions in mm.

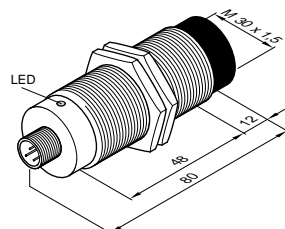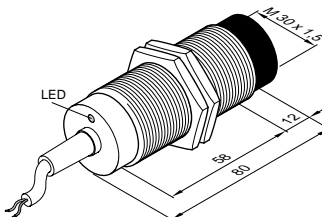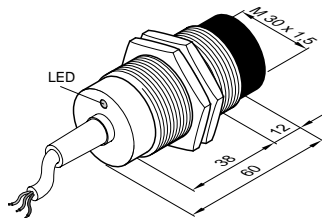

Accessories

2 meter (6 ft. 6 in.) AC Cable Assemblies for Quick Disconnect Sensors

68 Connector 8000-5130 PVC Straight
68 Connector 8000-5140 Right Angle


Change last digit of connector number to 5 for 5 meter cable

Refer to pages 116-121 for more cable information

Mounting Brackets – see Pages 114-115

Wiring Diagrams

Note: Wire colors are applicable to cable purchased from Altech

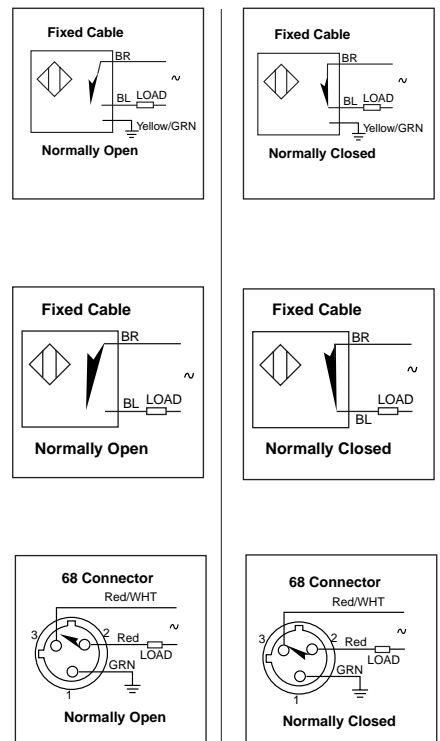

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[9916-2100](#) [9916-2300](#) [9916-2700](#) [9916-2600](#)