

DC - 3 WIRE – L SERIES
VERSA PROX LIMIT STYLE
Polyamide (PA 6.6) Housing
10-30V DC, 120mA
2 LEDs for Operating
Voltage & Output Energized

- 17 rotatable sensing head positions
- Programmable NO/NC outputs
- Rugged Housing
- Snap-together construction
- Separable mounting base
- Carries C mark

- IEC (529) IP67 (NEMA 1, 3, 4, 6, 12, 13) Protection
- Short Circuit Protection
- Overload Protection
- Reverse Polarity Protection
- Wire Break Resistance
- Temperature Range: -25 to 70°C (-13 to 158°F)

Metric/in. Conversion Table

3.0 mm = .11 in.	41 mm = 1.61 in.
5.0 mm = .20 in.	60 mm = 2.36 in.
7.0 mm = .27 in.	121 mm = 4.76 in.

This table converts millimeters to inches in reference to the illustrations included on these pages

Accessories

2 meter (6 ft. 6 in.) DC Cable Assemblies for Quick Disconnect Sensors

65 Connector	8000-5110	PVC, Straight
65 Connector	8000-5120	PVC, Right Angle
65 Connector	8000-5150	PVC, Right Angle, 2LED, NPN
65 Connector	8000-5160	PVC, Right Angle, 2LED, PNP


Change last digit of connector number to 5 for 5 meter cable

Refer to pages 116-121 for more cable information

Mounting Brackets – see Pages 114-115


Wiring Diagrams

Note: Wire colors are applicable on cables purchased from Altech

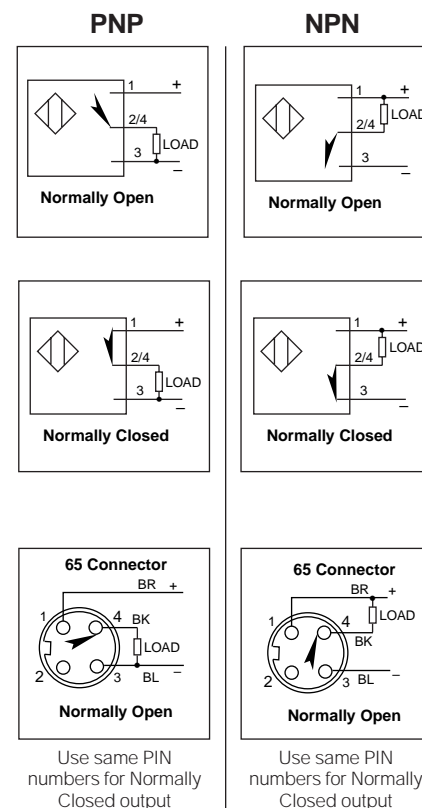

Screw Terminals

Screw terminals are located internally in housing for wire connections

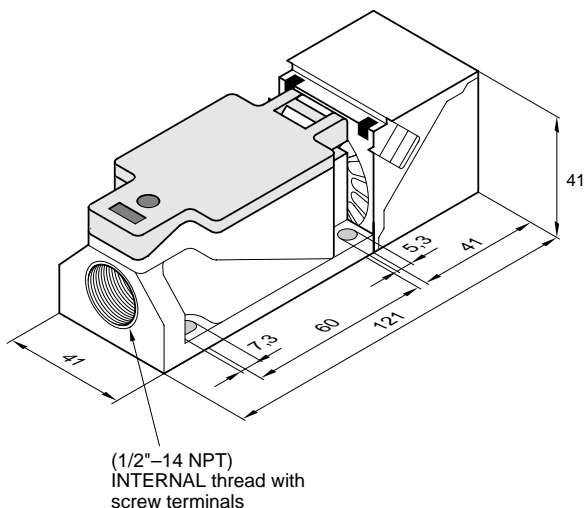


Note: Sensor dimensions in mm.

Alternative Connector Style

65 Style Connector –

4-pin Micro style, 12mm (.47 in.).

Flush		Non-Flush	
PNP	NPN	PNP	NPN
9883-2065	9883-2365	9883-2265	9883-2565

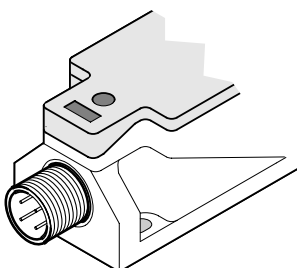

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[9883-2233](#)