

TK 3625 – Polystyrene and Polycarbonate – 360x254mm (14.2x10.0in.)

Standard Features

- **Protection Level:** IP66 (NEMA 4X)
- **Technical:** Smooth or Knockout Sidewalls
Gray or Tinted Transparent Cover ^①
Multiple Enclosure Mounting Options
- **Enclosure Material:** Polystyrene or Polycarbonate
- **Gasket Material:** Polyurethane
- **Color:** Light Gray
- **Temperature Range:** Polystyrene
-40°C to 70°C (-40°F to 158°F)
Polycarbonate
-35°C to 120°C (-31°F to 248°F)
- **Accessories:** See section below



Smooth Sidewalls

Polystyrene

Polycarbonate

Ordering Information	Height mm (in)	Cat. No.	Type	Cover Color	Std. Pk.	Cat. No.	Type	Cover Color	Std. Pk.
Enclosure - low cover	111 mm (4.37 in)	110-412	PS 3625-11-o	gray	1	120-412	PC 3625-11-o	gray	1
Enclosure - high cover	165 mm (6.50 in)	110-912	PS 3625-16-o	gray	1	120-912	PC 3625-16-o	gray	1
Enclosure - top hat cover	215 mm (8.46 in)	109-412	PS 3625-21-o	gray	1	121-412	PC 3625-21-o	gray	1
Enclosure - low cover	111 mm (4.37 in)	111-012	PS 3625-11-to	trans.	1	130-012	PC 3625-11-to	trans.	1
Enclosure - high cover	165 mm (6.50 in)	111-512	PS 3625-16-to	trans.	1	130-512	PC 3625-16-to	trans.	1
Enclosure - top hat cover	215 mm (8.46 in)	112-012	PS 3625-21-to	trans.	1	131-012	PC 3625-21-to	trans.	1

Sidewalls with PG Knockouts (metric available)

Polystyrene

Polycarbonate

Ordering Information	Height mm (in)	Cat. No.	Type	Cover Color	Std. Pk.	Cat. No.	Type	Cover Color	Std. Pk.
Enclosure - low cover	111 mm (4.37 in)	115-412	PS 3625-11	gray	1	125-412	PC 3625-11	gray	1
Enclosure - high cover	165 mm (6.50 in)	115-912	PS 3625-16	gray	1	125-912	PC 3625-16	gray	1
Enclosure - top hat cover	215 mm (8.46 in)	114-412	PS 3625-21	gray	1	126-412	PC 3625-21	gray	1
Enclosure - low cover	111 mm (4.37 in)	116-012	PS 3625-11-t	trans.	1	135-012	PC 3625-11-t	trans.	1
Enclosure - high cover	165 mm (6.50 in)	116-512	PS 3625-16-t	trans.	1	135-512	PC 3625-16-t	trans.	1
Enclosure - top hat cover	215 mm (8.46 in)	117-012	PS 3625-21-t	trans.	1	136-012	PC 3625-21-t	trans.	1

RK Enclosures with Terminal Blocks

Ordering Information	Height	Cat. No.	Type	Cover Color	Std. Pk.
Enclosure - 100 pole/10 AWG Terminal	111 mm (4.37 in)	626-404	RK3625	gray	1
Enclosure - DIN Rail only (2x) (TS35)	111 mm (4.37 in)	626-922	RK3625	gray	1

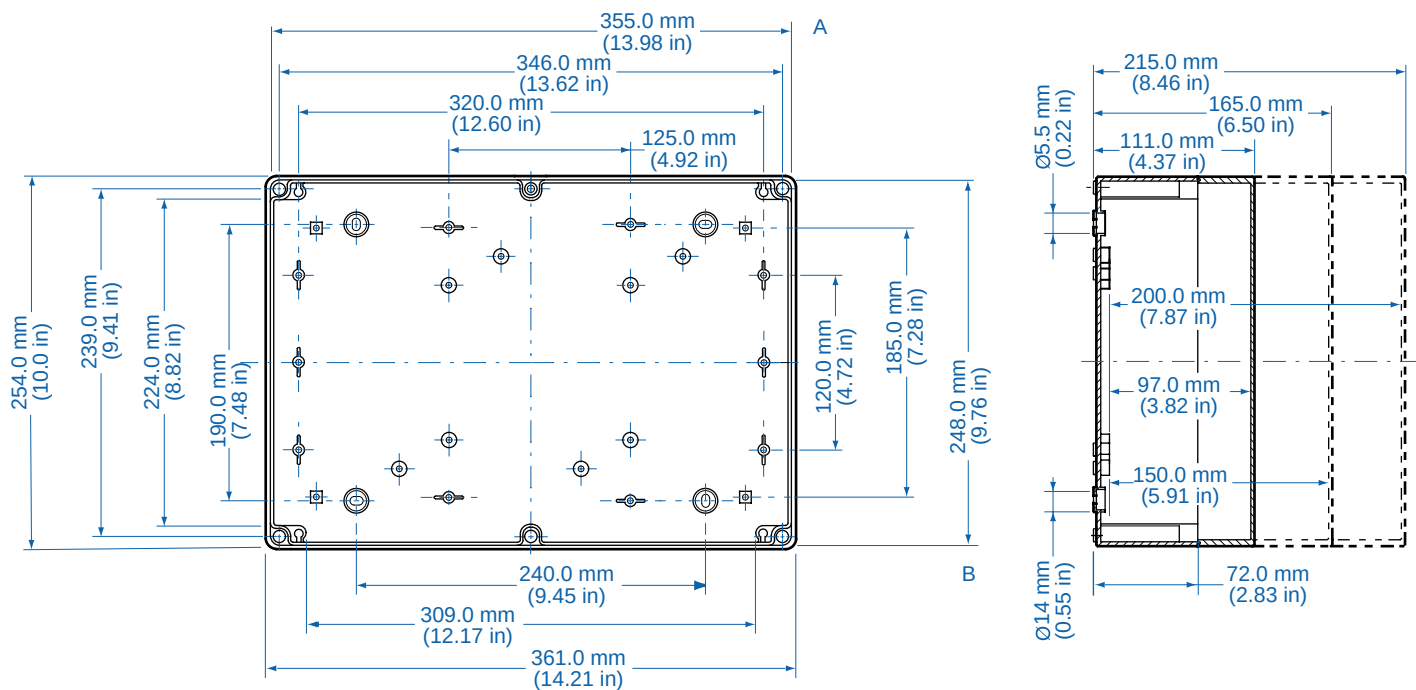
Accessories

Ordering Information	Cat. No.	Type	Std. Pk.
Mounting Plate	195-012	MP3625	1
DIN Rail TS35-336mm	Z-663	TS 35/ 336	1
Hinge Kit Set	190-005	HK2	1
Mounting Tab Kit	194-001	MT1	1

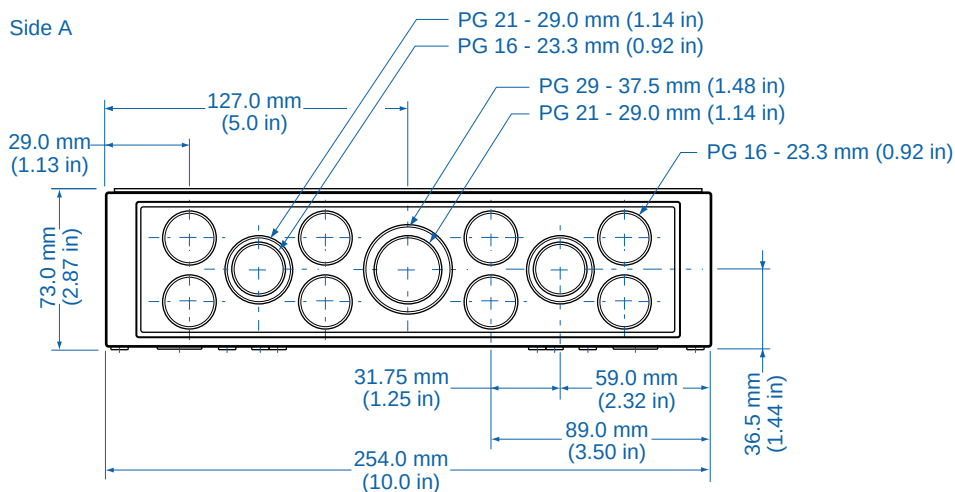
Please refer to pages 106-113 for additional accessories and detailed information.

^① Clear transparent lids available upon request

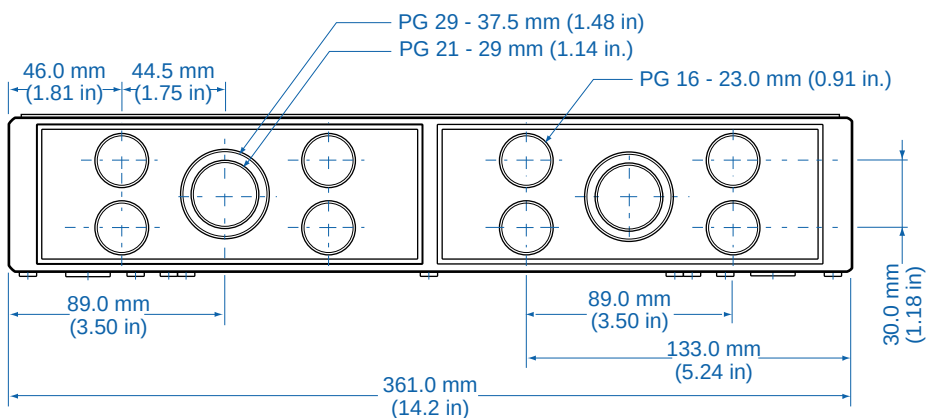
Dimensions

Knockout Positions ^②

Side A



Side B

^② Metric knockouts available upon request

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[116-012](#) [115-412](#) [115-912](#) [116-512](#)