

# Test Plugs 2 mm System



CE

Type

**MZS 2**

Shrouded Adapter 2mm plug to 4mm jack.

**MST S WS 30 AU**

2mm safety plug, spring loaded pin, gold plated, solder terminal 0.5mm2-1.0mm2, 1000V system.

Pin diameter

2 mm (0.078")

PART NO. / Housing color

● 973600100

● 973600101

2 mm (0.078")

● 975090700

● 975090701

● 975090702

● 975090703

● 975090704

● 975090705

● 975090706

● 975090707

● 975090709

## Technical Data

Contact Type	stationary
Connection Type	jack Ø4mm
Voltage Rating	30 VAC / 60 VDC
Measurement Category (IEC61010)	CAT I
Current Rating*	6A
Contact Resistance	6 mOhm

## Material Specifications

Plug	nickel plated brass
Contact Spring	-
Housing	PP

## Environmental Conditions

Temperature range	-20 °C to +60 °C (-4 to 140°F)
-------------------	--------------------------------

## Flamability Rating

Housing	UL94 HB
---------	---------

spring loaded pin
solder terminal
AC/DC 1000V
CAT III
10A
2 mOhm



gold plated copper-beryllium
gold plated brass
Polyamide

-15°C to +70°C (-5 to 158°F)
------------------------------

-

## Drawing

Measurements are shown in millimeters.  
Multiply by 0.03937 to convert to inches.

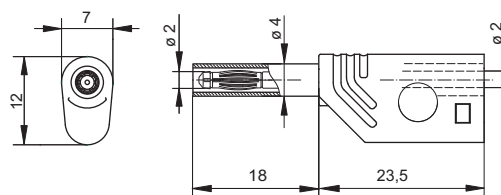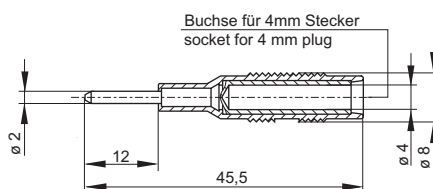

\* Please consider derating graph on page 80.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[975090706](#) [975090709](#) [975090703](#) [975090705](#) [975090702](#) [973600101](#) [975090700](#) [975090704](#) [975090707](#)  
[973600100](#) [975090701](#)