

Test Plugs 4 mm System



Type

LAS 30 / LAS 30 Au

4mm spring loaded plug, nickel/ gold plated contact spring, solder terminal up to 1.5mm².

Pin diameter

4 mm (0.157")

PART NO. / Housing color

Nickel Plated	Gold Plated
● 972518100	● 972518700
● 972518101	● 972518701
● 972518102	● 972518702
● 972518103	● 972518703
● 972518104	● 972518704



BUELA 20 K

4mm multi spring plug, flexible, insulated sleeve with 4mm cross hole, nickel plated brass, screw terminal max. 1.5mm².

4 mm (0.157")

● 930726100
● 930726101
● 930726102
● 930726103
● 930726104
○ 930726107

Technical Data

Contact Type	spring loaded pin
Connection Type	solder terminal max. 1.5mm ²
Voltage Rating	30 VAC / 60 VDC
Measurement Category (IEC61010)	CAT I
Current Rating*	32A
Contact Resistance	3 mOhm

Material Specifications

Plug	nickel plated brass; gold plated brass
Contact Spring	nickel pl. copper-beryllium; gold pl. copper-beryllium
Housing	PVC-P

Environmental Conditions

Temperature range	-25 °C to +70°C (-13 to 158°F)
-------------------	--------------------------------

Flamability Rating

Housing	-
---------	---

spring loaded pin
screw terminal max. 1.5mm ²
30 VAC / 60 VDC
CAT I
16A
3 mOhm



nickel plated brass
-
PVC-P

-25 °C to +70°C (-13 to 158°F)

-

Drawing

Measurements are shown in millimeters.
Multiply by 0.03937 to convert to inches.

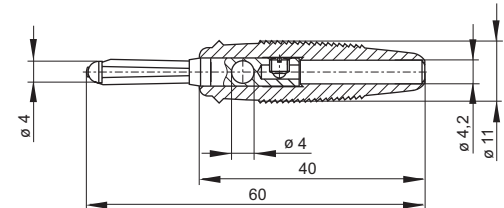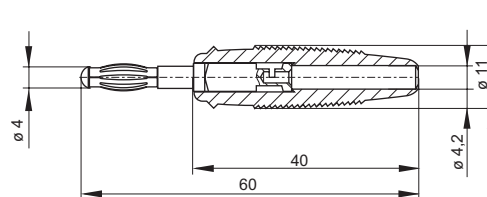

* Please consider derating graph on page 80.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[930726100](#) [930726101](#) [930726102](#) [930726103](#) [930726104](#) [972518103](#) [972518104](#) [972518102](#) [972518101](#)
[972518100](#)