

Test Jacks 4 mm System

Type



SEP 2610 F4,8

Safety press-in socket, 4 mm diameter, contact-protected, with 4.8 x 0.8 tab connector complying with DIN 46 244, gold-plated brass. For rapid installation into switch panels with wall thicknesses between 1-10 mm. Installation hole: 12.2 +/- 0.1 mm diameter. Entry chamfer: 0.5 x 45 degree.

Pin Diameter

2 mm

PART NO. / Housing color

- 972361100
- 972361101
- 972361102
- 972361103
- 972361104
- 972361188



SEP 2620 F6,3

Safety press-in socket, 4 mm diameter, contact-protected, with 6.3 x 0.8 tab connector complying with DIN 46244, gold-plated brass. For rapid installation into switch panels with wall thicknesses between 1-10 mm. Installation hole: 12.2 +/- 0.1 mm diameter. Entry chamfer: 0.5 x 45 degree.

2 mm

- 972362100
- 972362101
- 972362102
- 972362103
- 972362104
- 972362188



SEP 2630 S1,9

Gold-plated brass safety press-in socket, 4 mm diameter, contact-protected, with 1.9 mm soldering spike. For installation into switch panels with wall thicknesses between 1 mm and 10 mm. Installation hole: 12.2 +/- 0.1 mm diameter. Entry chamfer: 0.5 x 45 degree.

2 mm

- 972363100
- 972363101
- 972363102
- 972363103
- 972363104
- 972363188

Technical Data

Contact Type jack Ø 4 mm

Connection Type flat 4.8 x 0.8 mm tab

Voltage Rating AC/DC 1000 V

Measurement Category (IEC61010) CAT III

Current Rating* 24 A

Contact Resistance 5 mOhm

Mounting Type press in

Material Specifications

Jack Body gold plated brass

Contact Spring -

Housing PA

Environmental Conditions

Temperature Range -40°C to +80°C (-40 to 176°F)

Flamability Rating

Housing UL 94 V-2

jack Ø 4 mm

flat 6.3 x 0.8 mm tab

AC/DC 1000 V

CAT III

32 A

5 mOhm

press in

gold plated brass

-

PA

-40°C to +80°C (-40 to 176°F)

UL 94 V-2

jack Ø 4 mm

solder pin 1.9mm

AC/DC 1000V

CAT III

24 A

5 mOhm

press in

gold plated brass

-




PA

-40°C to +80°C (-40 to 176°F)

UL 94 V-2

Drawing

Measurements are shown in millimeters.
Multiply by 0.03937 to convert to inches.

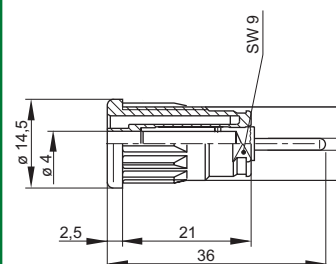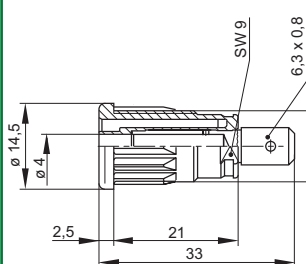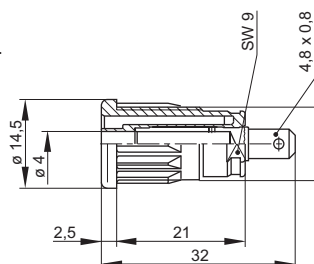

* Please consider derating graph on page 80.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[972363101](#) [972361103](#) [972363102](#) [972361100](#) [972362100](#) [972363103](#) [972363100](#) [972362188](#) [972362103](#)
[972362104](#) [972361102](#) [972361188](#) [972362101](#) [972363188](#) [972361104](#) [972361101](#) [972363104](#) [972362102](#)