

Type

# Clamp-type Test Probe 2 mm system



## KLEPS 2

Miniature clamp-type test probe with solder connection. Gold-plated sprung bronze contact hook for wires up to a maximum diameter of 2 mm. Remove actuator button for soldering, when cable is connected, press back on until it engages.

Clamping range  
Clamp type

2 mm  
contact hook

PART NO. / Housing color

931467100 ●  
931467101 ●



## KLEPS 2 BU

Miniature clamp-type test probe with 2 mm diameter socket connection. Gold-plated sprung copper beryllium contact hook for wires up to a maximum diameter of 2 mm. Suitable for connection to wire-wrap posts up to a maximum of 1 x 1 mm.

2 mm  
contact hook

973501100 ●  
973501101 ●

### Technical data

Type of termination	Solder Terminal
Rated voltage	30 VAC / 60 VDC
Measurement cat. acc. to IEC61010	CAT I
Rated current*	6 A
Contact resistance	15 mOhm

### Material Specifications

Contact material	contact hook: spring bronze
------------------	-----------------------------

Contact surface material	gold
Housing material	PA

### Environmental conditions

Temperature range	-25 °C to +100 °C
-------------------	-------------------

### Inflammability class

Housing (basic material)	UL 94 V-2
--------------------------	-----------

spring-loaded socket Ø 2 mm
30 VAC / 60 VDC
CAT I
6 A
15 mOhm

contact hook: bronze, contact spring: copper beryllium
---



gold
PA

-25 °C to +100 °C
-------------------

UL 94 V-2
-----------

### Drawing

Measurements are shown in millimeters.  
Multiply by 0.03937 to convert to inches.

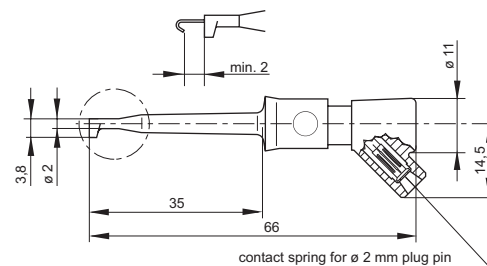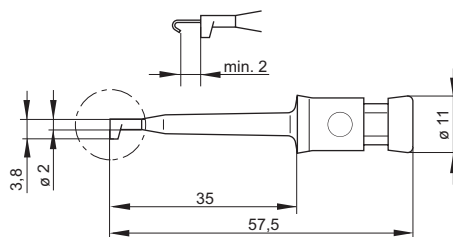

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[973501100](#) [973501101](#) [931467101](#) [931467100](#)